


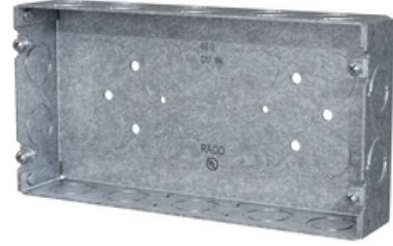

3-Gang Box, Welded, 1-5/8 in. Deep, Fourteen 1/2 & 3/4 in. Concentric KO's, Six 1/2 in. KO's, and Two 3/4 in. KO's

By Raco
Catalog # [952](#)



3-Gang Box, Welded, 1-5/8 in. Deep, Fourteen 1/2 & 3/4 in. Concentric KO's, Six 1/2 in. KO's, and Two 3/4 in. KO's

Features

- Gang boxes save time in installation, no need to gang boxes together.
- Have 1/2" and 3/4" concentric KO's for use with a wide variety of wiring methods.
- Bottom KO pattern, 3-1/2" and 2-3/4" at either end of box.
- Accepts two styles of covers, flat and 3/4" raised device cover.
- Use low voltage partitions #947 or #949.
- Spacing of devices match standard wall plates
- Used where multiple wiring devices are to be centrally located
- Supplied with fourteen 1/2 & 3/4 in. concentric knockouts
- 3/4 in. raised mud rings and flat covers available for all sizes
- 60 cu. in. capacity

General

Bracket Type	No Bracket
Color	Gray
EU RoHS Indicator	Contact Manufacturer
Knockouts	1/2 in;3/4 in;1/2-3/4 in Concentric
Material	Steel
Number of Gang(s)	3-Gang
Type	Box
UPC	050169009529
Wiring System	Conduit

Dimensions

Actual Depth	1.912 in
Cubic Capacity	60 cu.in
Depth	1.625 in
Height	4.526 in
Weight	1.5 lb
Width	8.69 in

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

Logistics

Carton Quantity	5
Pallet Quantity	720

Product Assets

[3D Product View - RACO_952](#)
[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - UL COC - E195978-1](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC_SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
RACO-952-SPEC-EN | REV 6/2024