




#14 Solid Insulated Copper Wire Pigtail, 6 in. Length (25/BE)

By Raco
Catalog # 982

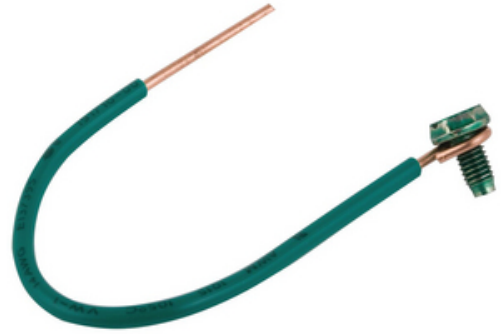

#14 Solid Insulated Copper Wire Pigtail, 6 in. Length (25/BE)

Features

- RACO® 6" and 8" ground pigtails feature 4-way slotted, phillips, hex-head) combo 10-32 captive screws
- #14 solid insulated copper wire
- Captive four-way combo head ground screw
- 6 in. wire length

General

Accessory Type	Box
EU RoHS Indicator	Contact Manufacturer
Type	Ground Screws
UPC	050169009826

Dimensions

Dimensions	6 in x 0.4 in x 0.5 in
Height	0.5 in
Length	6 in
Weight	0.015 lb
Width	0.4 in

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

Logistics

Carton Quantity	1000
Minimum Pack Quantity	1000
Packaging Type	Bundle
Pallet Quantity	64000

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[SDS - HCC SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand