




## #12 Solid Insulated Copper Wire Pigtail, 6 in. Length (25/BE)

By Raco  
Catalog # 983

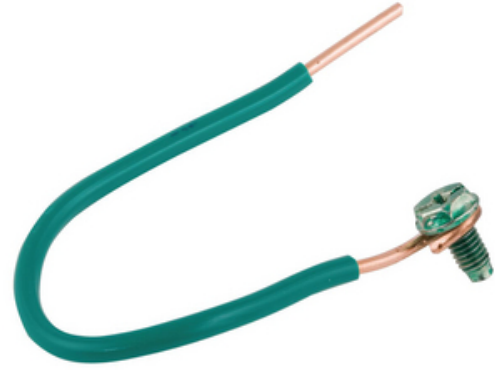

#12 Solid Insulated Copper Wire Pigtail, 6 in. Length (25/BE)

### Features

- RACO® 6" and 8" ground pigtails feature 4-way slotted, phillips, hex-head) combo 10-32 captive screws
- #12 solid insulated copper wire
- Captive four-way combo head ground screw
- 6 in. wire length
- Suitable for 10-32 threaded hole

### General

Accessory Type	Box
Catalog Number	983
EU RoHS Indicator	Contact Manufacturer
Type	Ground Screws
UPC	050169909836

### Dimensions

Dimensions	8 in x 0.4 in x 0.5 in
Height	0.5 in
Length	8 in
Weight	0.019 lb
Width	0.4 in

### Logistics

Carton Quantity	1000
Minimum Pack Quantity	1000
Packaging Type	Bundle
Pallet Quantity	80000

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[SDS - HCC\\_SDS](#)  
[Terms and Conditions - HCC Terms & Conditions](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
RACO-983-SPEC-EN | REV 6/2024