




2-Gang Wallbox, Gangable, 4-inch Deep, 2-inch Knockouts

By Raco
Catalog # 985

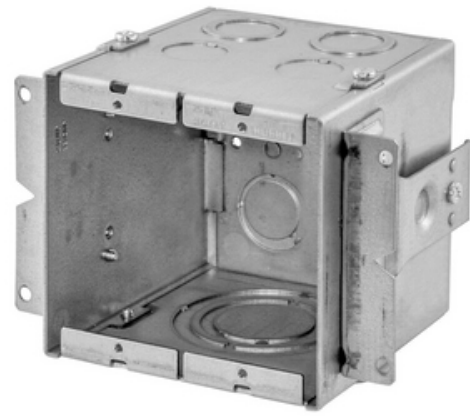

2-Gang Wallbox, Gangable, 4-inch Deep, 2-inch Knockouts

Features

- Knockouts from 1/2" up to 2"
- 4" depth accepts any device
- Concentric 1/2" - 3/4" knockouts for pre-connectorized AV cables
- Eccentric 1/2" - 3/4" knockouts
- Raised ground provision in each gang
- Accepts low voltage partition
- NEMA spaced device mounting, accepts industry standard wallplates
- Adjustable stud mounting brackets built in to accommodate different stud and sheetrock thickness
- Adjustable far side support
- Suitable for masonry application

General

Catalog Number	985
Drawn or Welded	Welded
Knockouts	1/2 in;1/2 - 3/4 in Combination (TKO)
Material	Steel
Number of Gang(s)	2-Gang
Type	Box
	Large Capacity
UPC	050169009857
Wiring System	Conduit

Dimensions

Actual Depth	4.165 in
Cubic Capacity	54 cu.in
Depth	4
Height	4.205 in
Weight	1.758 lb
Width	5.562 in

Certifications And Compliance

Certified Listed	cULus Listed
------------------	--------------

Logistics

Carton Quantity	10
Packaging Type	No Packaging
Pallet Quantity	560

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Sales Drawings - 985 Customer Drawing](#)
[SDS - HCC SDS](#)
[Sell Sheets - AV Wall Boxes Gangable, 4" Deep](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
RACO-985-SPEC-EN | REV 6/2024