



RMPIII Series

Single Pole Power Connectors

for High Amperage Power Applications



Harsh & Hazardous





RMP III SERIES

RMP III 300/400

RMP III MALE PLUG



Wide Range of
Cable Sizes, with
Cut-Off Points

**RMP III FEMALE
PLUG**




High Conductivity
Brass Contact



Non-Conductive
Locking Screw




Molded-In Strip
Gauge

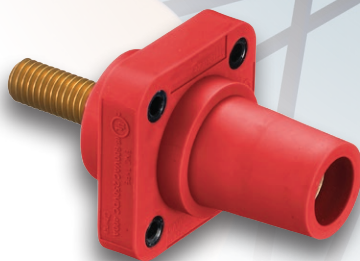

Female Receptacle, Stud Type



Female Receptacle, Double Set Screw

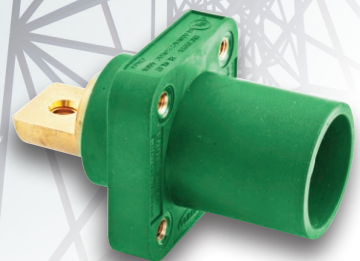

Male Receptacle, Bus Bar Mount

CONNECTORS


RMPIII SERIES



RMPIII300/400



RMPIII300/400
Plug

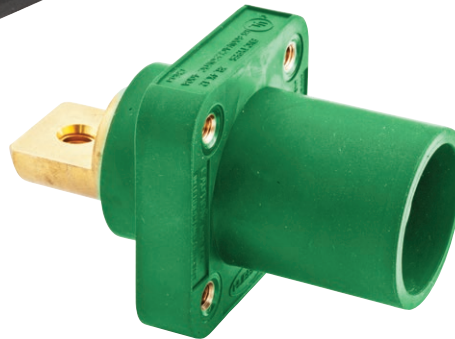

RMPIII300/400 Receptacle

UL and cUL Listed
UL Enclosure Types 3R, 4X, 12
UL1691 Standard (Single Pole
Locking Type Connectors)
Flammability: HB per UL94 or CSA
22.2.0.17



FEATURES-SPECIFICATIONS

Features:

- Plug design incorporates superior grip, for safe connection.
- Accommodates wide range of cables, with easily identifiable cable cut off points.
- Extra-long insulating inner sleeve reduces force required to install contacts, including special non-conductive locking screw thread that requires fewer turns for assembly, leading to quicker installation, with no need for additional tools.
- Rounded corners, which prevent snagging on other equipment, and non-conductive retaining screw lead to a safer plug design, during and after installation.
- Strip gauge molded into every plug and receptacle.
- Locking symbol on front of device provides clear indication that devices are properly connected; devices can be rotated 180 degrees to prevent unintended disconnects.
- High conductivity brass contacts provide high contact pressure and vibration-resistant connection, reducing operating temperatures and extending product life.

Materials:

- High Quality, Corrosion-Resistant Materials
 - » Insulators = Thermoplastic Elastomer (TPE)
 - » Contacts = High Conductivity Brass

Electrical Ratings:

- Voltage: 600VAC Maximum
- Amperage: 400A Maximum
- Wire Size: #6 AWG - 4/0 AWG
- Wire Type: Type SC/PPC Wire

AMPACITY RATINGS IN 40° AMBIENT


CABLE SIZE	90° C
#6 AWG	105A
#4 AWG	140A
#2 AWG	190A
#2/0 AWG	300A
#4/0 AWG	405A




RMPIII SERIES

RMPIII300/400

PLUG CATALOG LOGIC

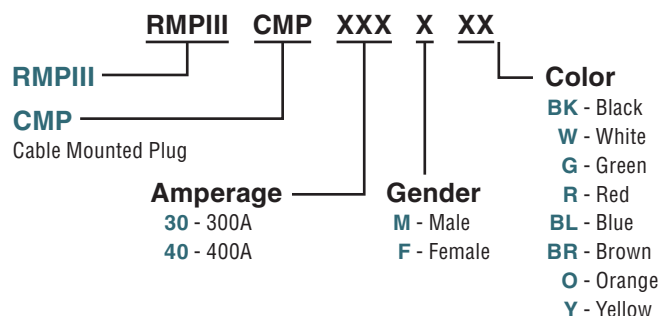

RECEPTACLE CATALOG LOGIC

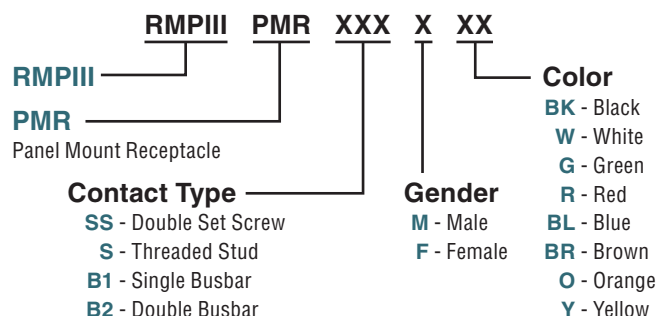

RMPIII CABLE MOUNTED PLUGS				
COLOR	300A MALE	400A MALE	300A FEMALE	400A FEMALE
BLACK	RMPIII-CMP-30-M-BK	RMPIII-CMP-40-M-BK	RMPIII-CMP-30-F-BK	RMPIII-CMP-40-F-BK
WHITE	RMPIII-CMP-30-M-W	RMPIII-CMP-40-M-W	RMPIII-CMP-30-F-W	RMPIII-CMP-40-F-W
GREEN	RMPIII-CMP-30-M-G	RMPIII-CMP-40-M-G	RMPIII-CMP-30-F-G	RMPIII-CMP-40-F-G
RED	RMPIII-CMP-30-M-R	RMPIII-CMP-40-M-R	RMPIII-CMP-30-F-R	RMPIII-CMP-40-F-R
BLUE	RMPIII-CMP-30-M-BL	RMPIII-CMP-40-M-BL	RMPIII-CMP-30-F-BL	RMPIII-CMP-40-F-BL
BROWN	RMPIII-CMP-30-M-BR	RMPIII-CMP-40-M-BR	RMPIII-CMP-30-F-BR	RMPIII-CMP-40-F-BR
ORANGE	RMPIII-CMP-30-M-O	RMPIII-CMP-40-M-O	RMPIII-CMP-30-F-O	RMPIII-CMP-40-F-O
YELLOW	RMPIII-CMP-30-M-Y	RMPIII-CMP-40-M-Y	RMPIII-CMP-30-F-Y	RMPIII-CMP-40-F-Y

COMPLETE PART NUMBER CONFIGURATIONS

RMPIII PANEL MOUNT RECEPTACLES

COLOR	CONTACT TYPE							
	DOUBLE SET SCREW-MALE	DOUBLE SET SCREW-FEMALE	THREADED STUD-MALE	THREADED STUD-FEMALE	SINGLE BUSBAR-MALE	SINGLE BUSBAR-FEMALE	DOUBLE BUSBAR-MALE	DOUBLE BUSBAR-FEMALE
BLACK	RMPIII-PMR-SS-M-BK	RMPIII-PMR-SS-F-BK	RMPIII-PMR-S-M-BK	RMPIII-PMR-S-F-BK	RMPIII-PMR-B1-M-BK	RMPIII-PMR-B1-F-BK	RMPIII-PMR-B2-M-BK	RMPIII-PMR-B2-F-BK
WHITE	RMPIII-PMR-SS-M-W	RMPIII-PMR-SS-F-W	RMPIII-PMR-S-M-W	RMPIII-PMR-S-F-W	RMPIII-PMR-B1-M-W	RMPIII-PMR-B1-F-W	RMPIII-PMR-B2-M-W	RMPIII-PMR-B2-F-W
GREEN	RMPIII-PMR-SS-M-G	RMPIII-PMR-SS-F-G	RMPIII-PMR-S-M-G	RMPIII-PMR-S-F-G	RMPIII-PMR-B1-M-G	RMPIII-PMR-B1-F-G	RMPIII-PMR-B2-M-G	RMPIII-PMR-B2-F-G
RED	RMPIII-PMR-SS-M-R	RMPIII-PMR-SS-F-R	RMPIII-PMR-S-M-R	RMPIII-PMR-S-F-R	RMPIII-PMR-B1-M-R	RMPIII-PMR-B1-F-R	RMPIII-PMR-B2-M-R	RMPIII-PMR-B2-F-R
BLUE	RMPIII-PMR-SS-M-BL	RMPIII-PMR-SS-F-BL	RMPIII-PMR-S-M-BL	RMPIII-PMR-S-F-BL	RMPIII-PMR-B1-M-BL	RMPIII-PMR-B1-F-BL	RMPIII-PMR-B2-M-BL	RMPIII-PMR-B2-F-BL
BROWN	RMPIII-PMR-SS-M-BR	RMPIII-PMR-SS-F-BR	RMPIII-PMR-S-M-BR	RMPIII-PMR-S-F-BR	RMPIII-PMR-B1-M-BR	RMPIII-PMR-B1-F-BR	RMPIII-PMR-B2-M-BR	RMPIII-PMR-B2-F-BR
ORANGE	RMPIII-PMR-SS-M-O	RMPIII-PMR-SS-F-O	RMPIII-PMR-S-M-O	RMPIII-PMR-S-F-O	RMPIII-PMR-B1-M-O	RMPIII-PMR-B1-F-O	RMPIII-PMR-B2-M-O	RMPIII-PMR-B2-F-O
YELLOW	RMPIII-PMR-SS-M-Y	RMPIII-PMR-SS-F-Y	RMPIII-PMR-S-M-Y	RMPIII-PMR-S-F-Y	RMPIII-PMR-B1-M-Y	RMPIII-PMR-B1-F-Y	RMPIII-PMR-B2-M-Y	RMPIII-PMR-B2-F-Y

CONNECTORS

RMPIII SERIES



RMPIII300/400

RMPIII ACCESSORIES

PROTECTIVE PLUG CAPS			WEATHER PROTECTIVE RECEPTACLE LIFT COVERS	
COLOR			COLOR	 
	FITS FEMALE DEVICES	FITS MALE DEVICES		ALL ONE COLOR CAPS AND BODIES
Black	RMPIII-FCAPBK	RMPIII-MCAPBK	Clear	RMPIII-NCC
			Black	RMPIII-NCABK
			White	RMPIII-NCAW
			Green	RMPIII-NCAG
			Red	RMPIII-NCAR
			Blue	RMPIII-NCABL
			Brown	RMPIII-NCABR
			Orange	RMPIII-NCAO
			Yellow	RMPIII-NCA Y

RMPIII300/400 SERIES


DIMENSIONS INCHES (mm)

	A	B	C	D
IN LINE PLUGS				
Male	7.01" (178.0)	1.38" (35.1)	1.48" (37.6)	4.78" (121.4)
Female	7.10" (180.5)	1.44" (36.6)	1.06" (27.0)	4.90" (121.3)


RMPIII300/400 SERIES

DESCRIPTION	DIMENSIONS INCHES (mm)							MOUNTING HOLE	TERMINATION
	A	B	C	D	E	F	G		
THREADED STUD									
Male & Female with through hole mounting	2.20" (55.9)	2.20" (55.9)	1.50" (38.1)	4.10" (104.3)	1.48" (47.4)	1.25" (31.7)	1.74" (44.2)	Through 4x Ø .20"	1/2-13 UNC-2A Threaded stud
DOUBLE SET SCREW									
Male & Female with through hole mounting	2.20" (55.9)	2.20" (55.9)	1.50" (38.1)	4.10" (104.3)	1.48" (47.4)	1.36" (34.5)	1.74" (44.2)	Through 4x Ø .20"	(2) 7/32 Socket Head set screws
BUSBAR TYPE									
Male & Female with threaded mounting holes	2.20" (55.9)	2.20" (55.9)	1.50" (38.1)	3.57" (90.7)	1.48" (37.6)	1.01" (25.7)	1.55" (39.4)	Threaded 4x #10-32	(1) 5/16-18 UNC-2B Threaded hole


DIMENSIONS

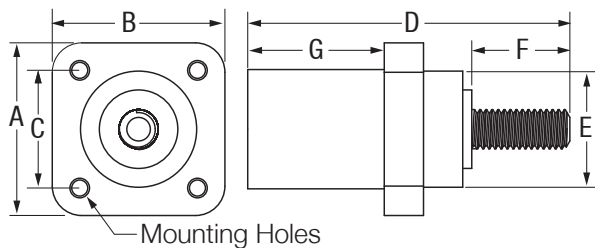


Threaded Stud (Male Shown)

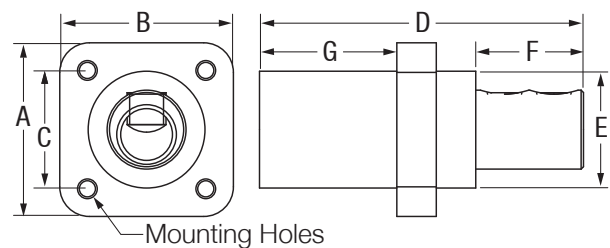

Double Set Screw (Male Shown)

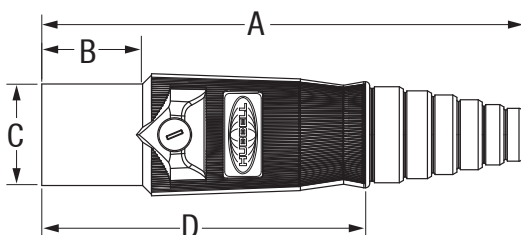

In Line Plug (Male Shown)

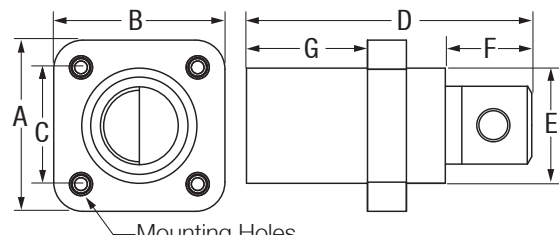


Busbar Type (Male Shown)



RMPIII SERIES

HIGHER AMPERAGE

RMPIII PANEL MOUNT HOUSINGS

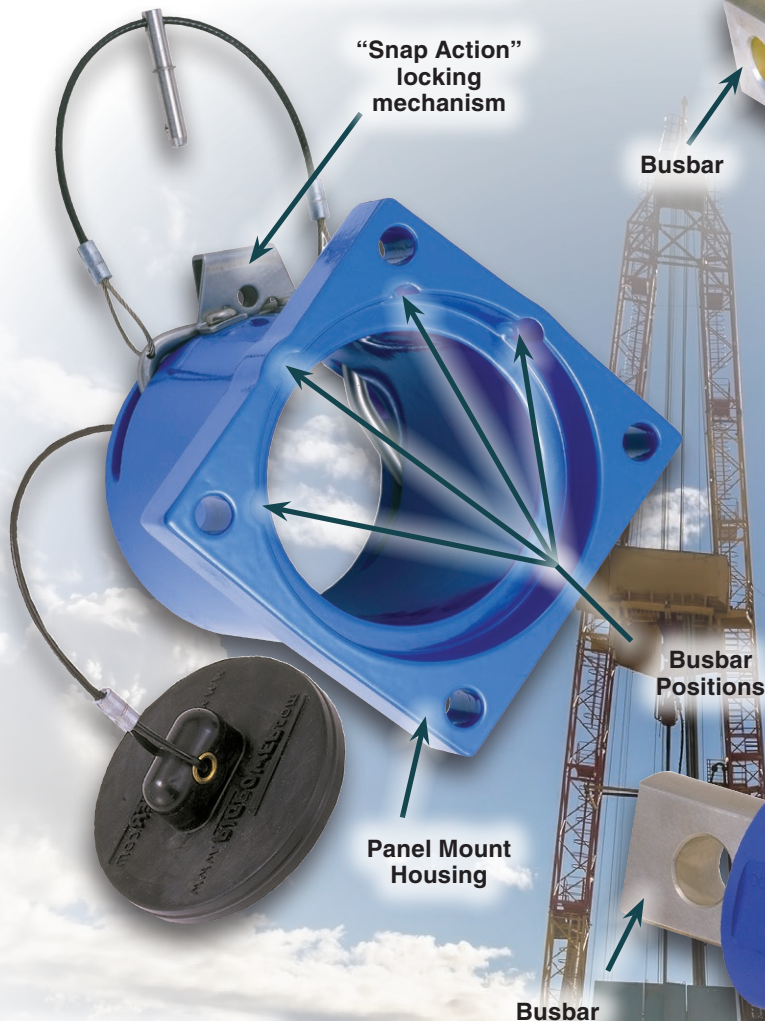


"Snap Action"
locking
mechanism

Busbar

Busbar
Positions

Panel Mount
Housing

RMPIII FEMALE RECEPTACLES

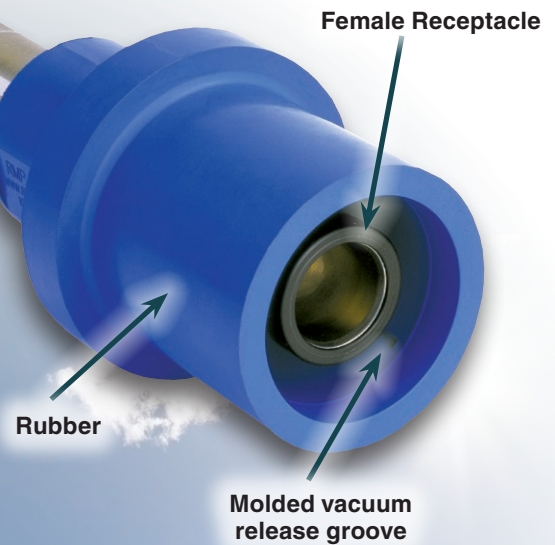


Female Receptacle

Rubber

Molded vacuum
release groove

RMPIII MALE RECEPTACLES

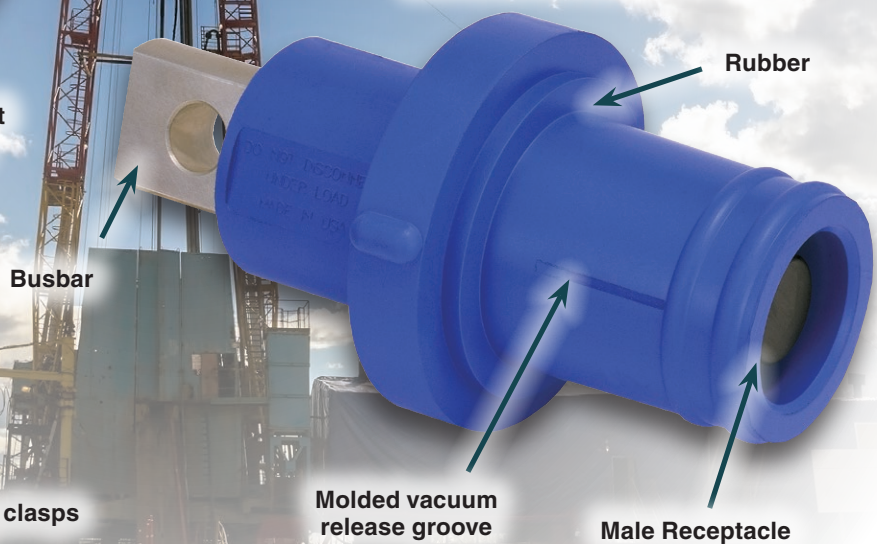

Rubber


Molded vacuum
release groove

Male Receptacle

FEMALE CONTACTS



MALE CONTACTS

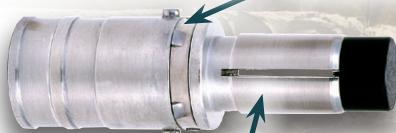

Six flared locking clasps


New contrast profile allows
increased contact pressure
with reduced insertion force.

CONNECTORS


RMPIII SERIES



HIGHER AMPERAGE RMPIII FEMALE PLUGS

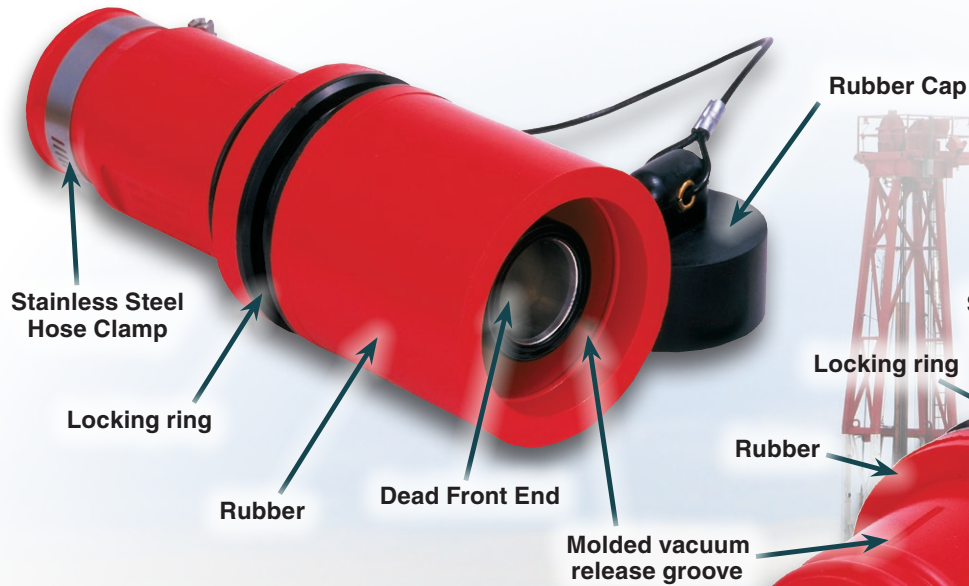

RMPIII MALE PLUGS

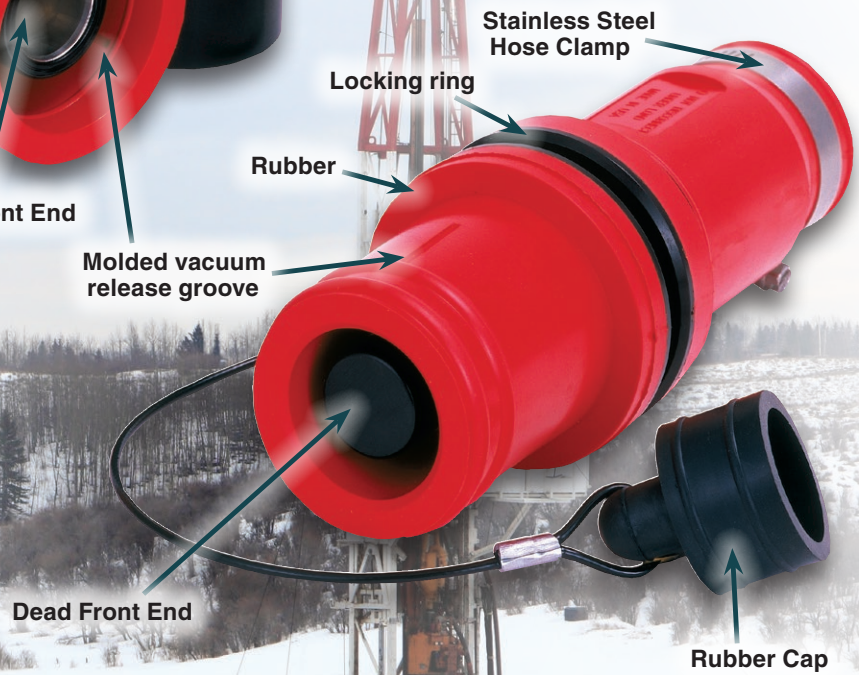

RMPIII IN-LINE CONNECTION





RMPIII SERIES

HIGHER AMPERAGE



RMP® III Series
Female Panel Mounted Receptacle



RMP® III Male Plugs

OSHA 1910 compliant
-40°C to +55°C ambient temperature
NEMA 3R
1000 Volts AC/DC
400-1135 Amps
Class 1 Div. 2



FEATURES-SPECIFICATIONS

Features:

- Single Pole Power Connectors
- Available in up to 10 Colors, for Phase-Specific Color Coding
- Available in Panel Mount Receptacles, Cable-Mounted Plugs, and In-Line Connectors
- Available in Male and Female Insert Configurations
- Rubber Plug/Receptacle Cap Included as Standard
- Angled Snap-Action Locking Bar on receptacles
- UL Certifications
- Easy, High-Strength Cable Termination, using Standard Crimp/Die Sets

Materials:

- High Quality, Corrosion Resistant Materials
 - » Hypalon Rubber Insulators
 - » Powder Coated, Copper-Free Aluminum Housings (when applicable)
- High Conductivity Copper Contacts and Busbars

Electrical Ratings:

- Suitable for a Wide Range of Maximum Amperages = 400A to 1135A (Cable Size Dependent)
- Suitable for up to 1000 VAC/DC
- Suitable for Wire Ranges between 4/0 AWG and 777 MCM

AMPACITY RATINGS IN 40° AMBIENT		
CABLE SIZE	90°	125°
4/0 MCM	364 AMPS	451 AMPS
262 MCM	428 AMPS	566 AMPS
313 MCM	513 AMPS	636 AMPS
373 MCM	548 AMPS	669 AMPS
444 MCM	642 AMPS	796 AMPS
535 MCM	724 AMPS	898 AMPS
646 MCM	814 AMPS	1009 AMPS
777 MCM	916 AMPS	1135 AMPS


CONNECTORS

RMPIII SERIES




HIGHER AMPERAGE

PLUG CATALOG LOGIC

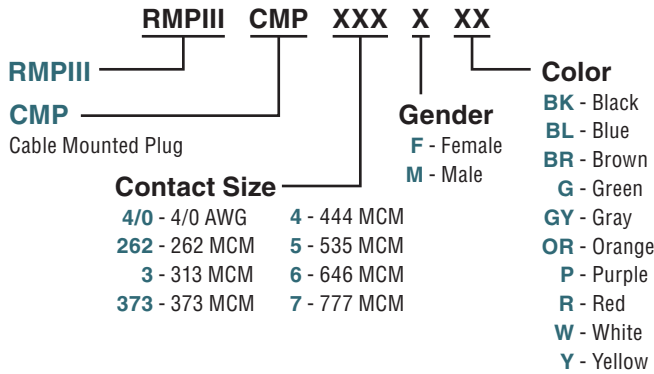

RECEPTACLE CATALOG LOGIC

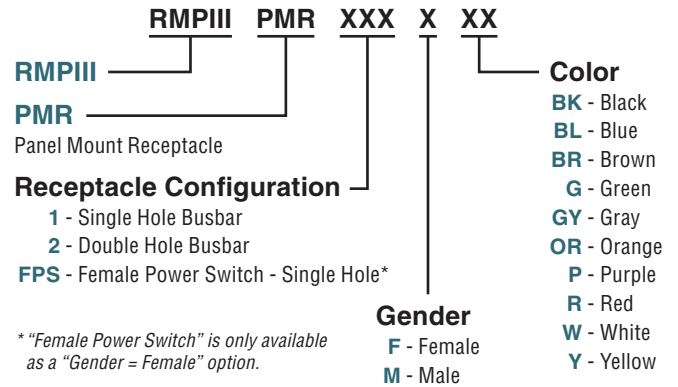

RMPIII CABLE MOUNTED PLUGS - MALE

COLOR	4/0 CONTACT	262 CONTACT	313 CONTACT	373 CONTACT	444 CONTACT	535 CONTACT	646 CONTACT	777 CONTACT
Black	RMPIII-CMP-4/0-M-BK	RMPIII-CMP-262-M-BK	RMPIII-CMP-3-M-BK	RMPIII-CMP-373-M-BK	RMPIII-CMP-4-M-BK	RMPIII-CMP-5-M-BK	RMPIII-CMP-6-M-BK	RMPIII-CMP-7-M-BK
Blue	RMPIII-CMP-4/0-M-BL	RMPIII-CMP-262-M-BL	RMPIII-CMP-3-M-BL	RMPIII-CMP-373-M-BL	RMPIII-CMP-4-M-BL	RMPIII-CMP-5-M-BL	RMPIII-CMP-6-M-BL	RMPIII-CMP-7-M-BL
Brown	RMPIII-CMP-4/0-M-BR	RMPIII-CMP-262-M-BR	RMPIII-CMP-3-M-BR	RMPIII-CMP-373-M-BR	RMPIII-CMP-4-M-BR	RMPIII-CMP-5-M-BR	RMPIII-CMP-6-M-BR	RMPIII-CMP-7-M-BR
Green	RMPIII-CMP-4/0-M-G	RMPIII-CMP-262-M-G	RMPIII-CMP-3-M-G	RMPIII-CMP-373-M-G	RMPIII-CMP-4-M-G	RMPIII-CMP-5-M-G	RMPIII-CMP-6-M-G	RMPIII-CMP-7-M-G
Gray	RMPIII-CMP-4/0-M-GY	RMPIII-CMP-262-M-GY	RMPIII-CMP-3-M-GY	RMPIII-CMP-373-M-GY	RMPIII-CMP-4-M-GY	RMPIII-CMP-5-M-GY	RMPIII-CMP-6-M-GY	RMPIII-CMP-7-M-GY
Orange	RMPIII-CMP-4/0-M-OR	RMPIII-CMP-262-M-OR	RMPIII-CMP-3-M-OR	RMPIII-CMP-373-M-OR	RMPIII-CMP-4-M-OR	RMPIII-CMP-5-M-OR	RMPIII-CMP-6-M-OR	RMPIII-CMP-7-M-OR
Purple	RMPIII-CMP-4/0-M-P	RMPIII-CMP-262-M-P	RMPIII-CMP-3-M-P	RMPIII-CMP-373-M-P	RMPIII-CMP-4-M-P	RMPIII-CMP-5-M-P	RMPIII-CMP-6-M-P	RMPIII-CMP-7-M-P
Red	RMPIII-CMP-4/0-M-R	RMPIII-CMP-262-M-R	RMPIII-CMP-3-M-R	RMPIII-CMP-373-M-R	RMPIII-CMP-4-M-R	RMPIII-CMP-5-M-R	RMPIII-CMP-6-M-R	RMPIII-CMP-7-M-R
White	RMPIII-CMP-4/0-M-W	RMPIII-CMP-262-M-W	RMPIII-CMP-3-M-W	RMPIII-CMP-373-M-W	RMPIII-CMP-4-M-W	RMPIII-CMP-5-M-W	RMPIII-CMP-6-M-W	RMPIII-CMP-7-M-W
Yellow	RMPIII-CMP-4/0-M-Y	RMPIII-CMP-262-M-Y	RMPIII-CMP-3-M-Y	RMPIII-CMP-373-M-Y	RMPIII-CMP-4-M-Y	RMPIII-CMP-5-M-Y	RMPIII-CMP-6-M-Y	RMPIII-CMP-7-M-Y

RMPIII CABLE MOUNTED PLUGS - FEMALE

Black	RMPIII-CMP-4/0-F-BK	RMPIII-CMP-262-F-BK	RMPIII-CMP-3-F-BK	RMPIII-CMP-373-F-BK	RMPIII-CMP-4-F-BK	RMPIII-CMP-5-F-BK	RMPIII-CMP-6-F-BK	RMPIII-CMP-7-F-BK
Blue	RMPIII-CMP-4/0-F-BL	RMPIII-CMP-262-F-BL	RMPIII-CMP-3-F-BL	RMPIII-CMP-373-F-BL	RMPIII-CMP-4-F-BL	RMPIII-CMP-5-F-BL	RMPIII-CMP-6-F-BL	RMPIII-CMP-7-F-BL
Brown	RMPIII-CMP-4/0-F-BR	RMPIII-CMP-262-F-BR	RMPIII-CMP-3-F-BR	RMPIII-CMP-373-F-BR	RMPIII-CMP-4-F-BR	RMPIII-CMP-5-F-BR	RMPIII-CMP-6-F-BR	RMPIII-CMP-7-F-BR
Green	RMPIII-CMP-4/0-F-G	RMPIII-CMP-262-F-G	RMPIII-CMP-3-F-G	RMPIII-CMP-373-F-G	RMPIII-CMP-4-F-G	RMPIII-CMP-5-F-G	RMPIII-CMP-6-F-G	RMPIII-CMP-7-F-G
Gray	RMPIII-CMP-4/0-F-GY	RMPIII-CMP-262-F-GY	RMPIII-CMP-3-F-GY	RMPIII-CMP-373-F-GY	RMPIII-CMP-4-F-GY	RMPIII-CMP-5-F-GY	RMPIII-CMP-6-F-GY	RMPIII-CMP-7-F-GY
Orange	RMPIII-CMP-4/0-F-OR	RMPIII-CMP-262-F-OR	RMPIII-CMP-3-F-OR	RMPIII-CMP-373-F-OR	RMPIII-CMP-4-F-OR	RMPIII-CMP-5-F-OR	RMPIII-CMP-6-F-OR	RMPIII-CMP-7-F-OR
Purple	RMPIII-CMP-4/0-F-P	RMPIII-CMP-262-F-P	RMPIII-CMP-3-F-P	RMPIII-CMP-373-F-P	RMPIII-CMP-4-F-P	RMPIII-CMP-5-F-P	RMPIII-CMP-6-F-P	RMPIII-CMP-7-F-P
Red	RMPIII-CMP-4/0-F-R	RMPIII-CMP-262-F-R	RMPIII-CMP-3-F-R	RMPIII-CMP-373-F-R	RMPIII-CMP-4-F-R	RMPIII-CMP-5-F-R	RMPIII-CMP-6-F-R	RMPIII-CMP-7-F-R
White	RMPIII-CMP-4/0-F-W	RMPIII-CMP-262-F-W	RMPIII-CMP-3-F-W	RMPIII-CMP-373-F-W	RMPIII-CMP-4-F-W	RMPIII-CMP-5-F-W	RMPIII-CMP-6-F-W	RMPIII-CMP-7-F-W
Yellow	RMPIII-CMP-4/0-F-Y	RMPIII-CMP-262-F-Y	RMPIII-CMP-3-F-Y	RMPIII-CMP-373-F-Y	RMPIII-CMP-4-F-Y	RMPIII-CMP-5-F-Y	RMPIII-CMP-6-F-Y	RMPIII-CMP-7-F-Y

COMPLETE PART NUMBER CONFIGURATIONS

RMPIII PANEL MOUNT RECEPTACLES					POWER SWITCH RECEPTACLE
COLOR	SINGLE HOLE MALE	DOUBLE HOLE MALE	SINGLE HOLE FEMALE	DOUBLE HOLE FEMALE	FEMALE
Black	RMPIII-PMR-1-M-BK	RMPIII-PMR-2-M-BK	RMPIII-PMR-1-F-BK	RMPIII-PMR-2-F-BK	RMPIII-PMR-FPS-BK
Blue	RMPIII-PMR-1-M-BL	RMPIII-PMR-2-M-BL	RMPIII-PMR-1-F-BL	RMPIII-PMR-2-F-BL	RMPIII-PMR-FPS-BL
Brown	RMPIII-PMR-1-M-BR	RMPIII-PMR-2-M-BR	RMPIII-PMR-1-F-BR	RMPIII-PMR-2-F-BR	RMPIII-PMR-FPS-BR
Green	RMPIII-PMR-1-M-G	RMPIII-PMR-2-M-G	RMPIII-PMR-1-F-G	RMPIII-PMR-2-F-G	RMPIII-PMR-FPS-G
Gray	RMPIII-PMR-1-M-GY	RMPIII-PMR-2-M-GY	RMPIII-PMR-1-F-GY	RMPIII-PMR-2-F-GY	RMPIII-PMR-FPS-GY
Orange	RMPIII-PMR-1-M-OR	RMPIII-PMR-2-M-OR	RMPIII-PMR-1-F-OR	RMPIII-PMR-2-F-OR	RMPIII-PMR-FPS-OR
Purple	RMPIII-PMR-1-M-P	RMPIII-PMR-2-M-P	RMPIII-PMR-1-F-P	RMPIII-PMR-2-F-P	RMPIII-PMR-FPS-P
Red	RMPIII-PMR-1-M-R	RMPIII-PMR-2-M-R	RMPIII-PMR-1-F-R	RMPIII-PMR-2-F-R	RMPIII-PMR-FPS-R
White	RMPIII-PMR-1-M-W	RMPIII-PMR-2-M-W	RMPIII-PMR-1-F-W	RMPIII-PMR-2-F-W	RMPIII-PMR-FPS-W
Yellow	RMPIII-PMR-1-M-Y	RMPIII-PMR-2-M-Y	RMPIII-PMR-1-F-Y	RMPIII-PMR-2-F-Y	RMPIII-PMR-FPS-Y





RMP III SERIES

RMPIII ACCESSORIES AND REPLACEMENT PARTS

RMPIII COUPLERS	
CATALOG NUMBER	
RMP-CMR-BK	
RMP-CMR-BL	
RMP-CMR-BR	
RMP-CMR-G	
RMP-CMR-GY	
RMP-CMR-OR	
RMP-CMR-P	
RMP-CMR-R	
RMP-CMR-W	
RMP-CMR-Y	
RMP-CMR-AL	

BULKHEAD MOUNTED COUPLER	
COLOR	CATALOG NUMBER
Black	RMP-BMC-BK
Blue	RMP-BMC-BL
Brown	RMP-BMC-BR
Green	RMP-BMC-G
Gray	RMP-BMC-GY
Orange	RMP-BMC-OR
Purple	RMP-BMC-P
Red	RMP-BMC-R
White	RMP-BMC-W
Yellow	RMP-BMC-Y



RMPIII CONTACTS		
	CATALOG NUMBER	
	MALE CONTACTS	FEMALE CONTACTS
—	RMP-C-4/ØM	RMP-C-4/ØF
—	RMP-C-262M	RMP-C-262F
—	RMP-C-3M	RMP-C-3F
—	RMP-C-373M	RMP-C-373F
—	RMP-C-4M	RMP-C-4F
—	RMP-C-5M	RMP-C-5F
—	RMP-C-6M	RMP-C-6F
—	RMP-C-7M	RMP-C-7F

Cable Size 4/0
MCM Through
777 MCM


GROUNDING RECEPTACLES AND PLUGS	
CATALOG NUMBER	PART DESCRIPTION
RMP-FGP-4	Female Flange Mounted Grounding Plug
RMP-MGR	Male Flange Mounted Grounding Receptacle
RMP-FGR	Female Grounding Receptacle for 5/8 Stud
RMP-MGP-4	Male Grounding Pin for 5/8 Stud

RMPIII ACCESSORIES	
CATALOG NUMBER	PART DESCRIPTION
DT-002	Insulator Disassembly Tool

RMPIII INSULATORS		
	CATALOG NUMBER	
COLOR	MALE INSULATORS	FEMALE INSULATORS
Black	RMPIII-CMP-M-BK	RMPIII-CMP-F-BK
Blue	RMPIII-CMP-M-BL	RMPIII-CMP-F-BL
Brown	RMPIII-CMP-M-BR	RMPIII-CMP-F-BR
Green	RMPIII-CMP-M-G	RMPIII-CMP-F-G
Gray	RMPIII-CMP-M-GY	RMPIII-CMP-F-GY
Orange	RMPIII-CMP-M-OR	RMPIII-CMP-F-OR
Purple	RMPIII-CMP-M-P	RMPIII-CMP-F-P
Red	RMPIII-CMP-M-R	RMPIII-CMP-F-R
White	RMPIII-CMP-M-W	RMPIII-CMP-F-W
Yellow	RMPIII-CMP-M-Y	RMPIII-CMP-F-Y


DOUBLE HOLE LUGS	
CATALOG NUMBER	PART DESCRIPTION
QS-535-L	535 MCM Double Hole Lug
QS-646-L	646 MCM Double Hole Lug
QS-777-L	777 MCM Double Hole Lug

30°-45° REVERSIBLE LOCKING BUSBAR LUGS	
CATALOG NUMBER	PART DESCRIPTION
SL-535-AL	535 MCM 30°/45° Reversible Locking Busbar Lug
SL-646-AL	646 MCM 30°/45° Reversible Locking Busbar Lug
SL-777-AL	777 MCM 30°/45° Reversible Locking Busbar Lug

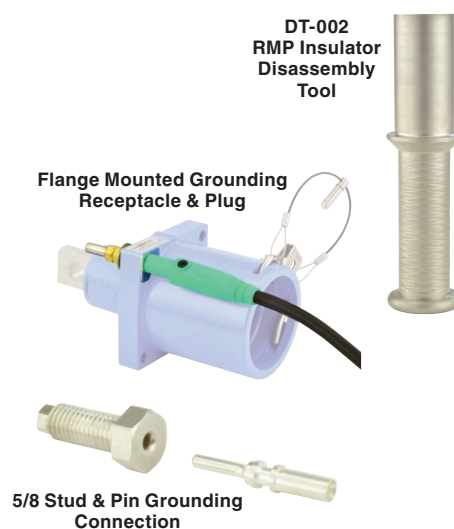




PANEL MOUNTED RECEPTACLE (PMR) MOUNTING DIMENSIONS

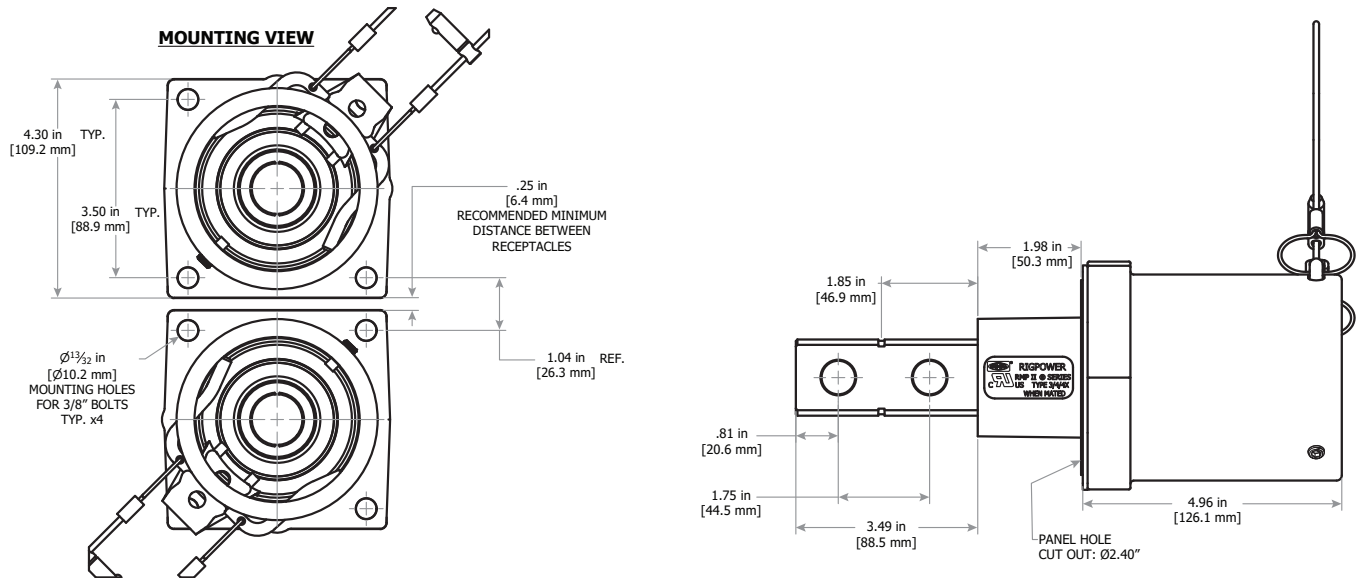

CABLE MOUNTED PLUG (CMP) DIMENSIONS

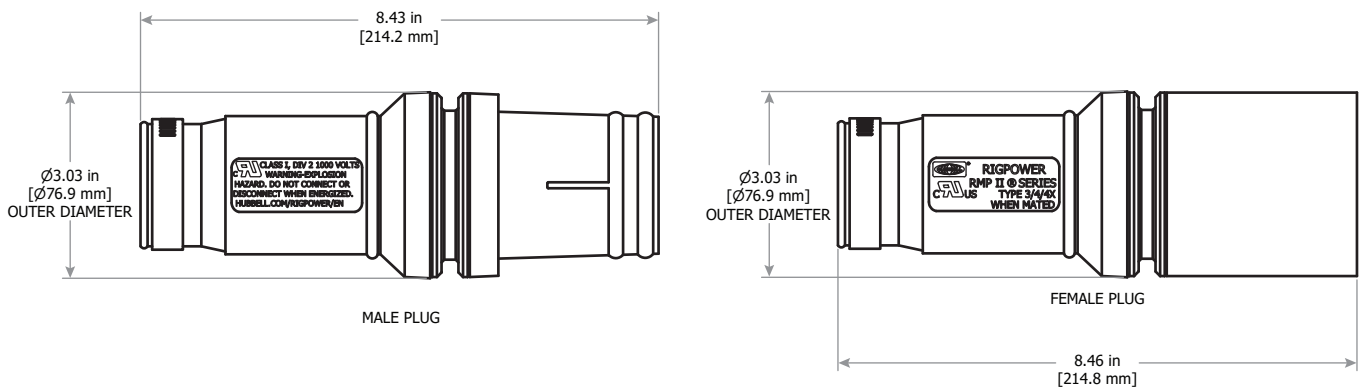



Harsh & Hazardous

Hubbell RigPower

2112 Fenton Logistics Park Blvd.

Fenton, MO 63026

Phone: (281) 445-7400

www.hubbell.com/rigpower/en