




## RIGID BODIES AND ASSEMBLIES

LB Assembly  
N/A

C13

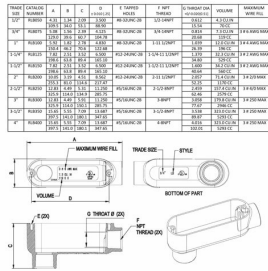

Catalog #: RLB050

### APPLICATIONS

For use with threaded rigid/IMC conduit for pulling access or to split a run into multiple directions. Removable cover allows access for maintenance and making taps and splices to conductors.  
N/A

### PRODUCT FEATURES

- Durable die cast aluminum construction
- Premium powder coat finish
- Includes NBR synthetic rubber gasket
- Stamped aluminum cover
- Combination head screw

### UL LISTED

File E331564

### NEMA

NEMA 3R rated

### NEC

2014 NEC® compliant

### GENERAL PRODUCT INFORMATION

Trade Size: 1/2 in.

### DRAWING DIMENSIONS

- Dimension A: 4.31 in.
- Dimension B: 1.34 in.
- Dimension C: 2.09 in.
- Dimension D: 3.50 in.
- Dimension E: Tapped holes #8-32UNC-2B
- Thread Spec. F: 1/2-14NPT
- Dimension G: .612 in.

### PRODUCT MEASUREMENTS

Cubic Inches (cm<sup>3</sup>): 4.3 (70.5)

### PACKAGING

- Package Type: Carton
- Ship Carton Qty.: 10
- Product UPC-A Labeled: Yes
- Weight (Lbs. Per/C): 30.00
- Ship Carton Length (in.): 4.88
- Ship Carton Width (in.): 4.50
- Ship Carton Height (in.): 7.50
- Ctn Weight (Lbs.): 3.00
- UPC Number: 092326211918
- I2of5: 30092326211919