




RIGID BODIES AND ASSEMBLIES

LL Assembly
N/A

C13

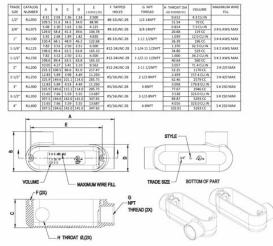

Catalog #: RLL125

APPLICATIONS

For use with threaded rigid/IMC conduit for pulling access or to split a run into multiple directions. Removable cover allows access for maintenance and making taps and splices to conductors.
N/A

PRODUCT FEATURES

- Durable die cast aluminum construction
- Premium powder coat finish
- Includes NBR synthetic rubber gasket
- Stamped aluminum cover
- Combination head screw

UL LISTED

File E331564

NEMA

NEMA 3R rated

NEC

2014 NEC® compliant

GENERAL PRODUCT INFORMATION

Trade Size: 1-1/4 in.

DRAWING DIMENSIONS

- Dimension A: 7.82 in.
- Dimension B: 3.52 in.
- Dimension C: 2.50 in.
- Dimension D: 2.51 in.
- Dimension E: 6.500 in.
- Dimension F: Tapped holes #12-24UNC-2B
- Dimension G: 1-1/4 - 11 1/2NPT
- Dimension H: 1.370 in.

PRODUCT MEASUREMENTS

Cubic Inches (cm3): 30.8 (504)

PACKAGING

- Package Type: Carton
- Ship Carton Qty.: 2
- Product UPC-A Labeled: Yes
- Weight (Lbs. Per/C): 120.00
- Ship Carton Length (in.): 9.00
- Ship Carton Width (in.): 4.13
- Ship Carton Height (in.): 6.13
- Ctn Weight (Lbs.): 2.40
- UPC Number: 092326213257
- I2of5: 30092326213258