




PORTABLE SPIKE LIGHTS

Portable Spike Lights
75-150 Watt Par 38 Lamps / CFL Compatible

D24.1

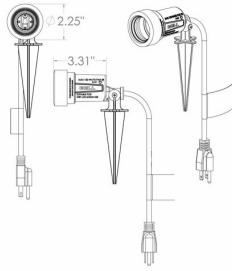

Catalog #: SL101B

APPLICATIONS

For general outdoor lighting in wet, damp or dry locations
N/A

PRODUCT FEATURES

Rugged die cast construction
State-of-the-art powder coat finish provides maximum weatherability and scratch resistance
Locking swivel knuckle assures positive lamp positioning and provides pin-point directional aiming
SPLED2Z - Long lasting energy efficient 6.5 Watts / 350 Lumens
5792-0 has 6 ft. cord

NEMA

3R Rated

NEC

2014 Compliant

GENERAL PRODUCT INFORMATION

Color: Bronze

PRODUCT MEASUREMENTS

Wt. Ea. (Lbs.): 0.580

PACKAGING

Package Type: Clamshell
Std. Pkg.: 10
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 58.00
Ship Carton Length (in.): 22.00
Ship Carton Width (in.): 6.00
Ship Carton Height (in.): 6.50
Ctn Weight (Lbs.): 5.80
Pallet Qty: 840.00
UPC Number: 092326110990
I2of5: 30092326110991