




CCL

CENTER-LENS TROFFER

tradeSELECT®

FEATURES

- 2'x2' and 2'x4' recessed sizes
- Choice of two color temperatures
- 80+ CRI
- 0–10V dimming, standard
- Universal voltage (120–277V)
- 3,300 to 5,000 nominal lumens
- Up to 118 lumens per watt
- Emergency battery backup available
- 5-Wire flex available

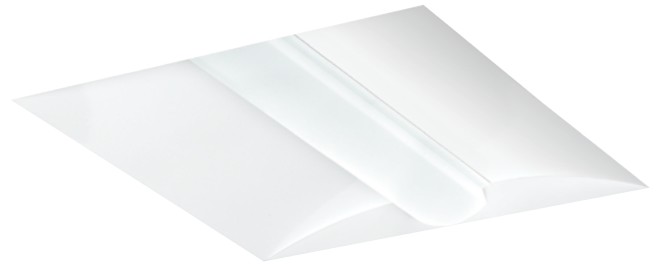

SPECIFICATIONS

OPTICS

- Frosted acrylic lens

INSTALLATION

- Fully assembled for quick installation

ELECTRICAL

- 54,000 hour LEDs at L70 for reduced maintenance

CERTIFICATIONS

- All luminaires are built to UL 1598 standards and bear appropriate CSA labels
- Damp location label standard
- Emergency-equipped fixtures labeled UL 924 unless specified
- IC rated

CERTIFICATIONS (CONTINUED)

- DLC® (DesignLights Consortium) Qualified. Please refer to the DLC website for specific product qualifications at www.designlights.org

WARRANTY

- 5 year warranty
- See [HLI Standard Warranty](#) for additional information

ORDERING GUIDE


Catalog Number	Description	Delivered Lumens	Watts	LPW	Qty on Pallet
CCL22-3335	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 3500K	3223	29	112	40
CCL22-3335-C588	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 3500K, 5-Wire Flex ¹				
CCL22-3335-ELL14	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 3500K, 1400lm Battery Pack ¹				
CCL22-3340	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 4000K	3345	29	116	40
CCL22-3340-C588	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 4000K, 5-Wire Flex ¹				
CCL22-3340-ELL14	2 x 2 Center Lens LED Troffer, 3,300 Lumens, 4000K, 1400lm Battery Pack ¹				
CCL24-5035	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 3500K	5001	44	114	20
CCL24-5035-C588	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 3500K, 5-Wire Flex ¹				
CCL24-5035-ELL14	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 3500K, 1400lm Battery Pack ¹				
CCL24-5040	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 4000K	5191	44	118	20
CCL24-5040-C588	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 4000K, 5-Wire Flex ¹				
CCL24-5040-ELL14	2 x 4 Center Lens LED Troffer, 5,000 Lumens, 4000K, 1400lm Battery Pack ¹				

Accessories (Order Separately)	
FK22	2' x 2' Single Flange Kit (Shipped separately)
FK24	2' x 4' Single Flange Kit (Shipped separately)

KEY DATA	
Lumen Range	3223–5191
Wattage Range	29–44
Efficacy Range (LPW)	112–118
Reported Life (Hours)	L70/54,000

Notes:
¹ Not stocked; ships in 5-10 days.

DIMENSIONS

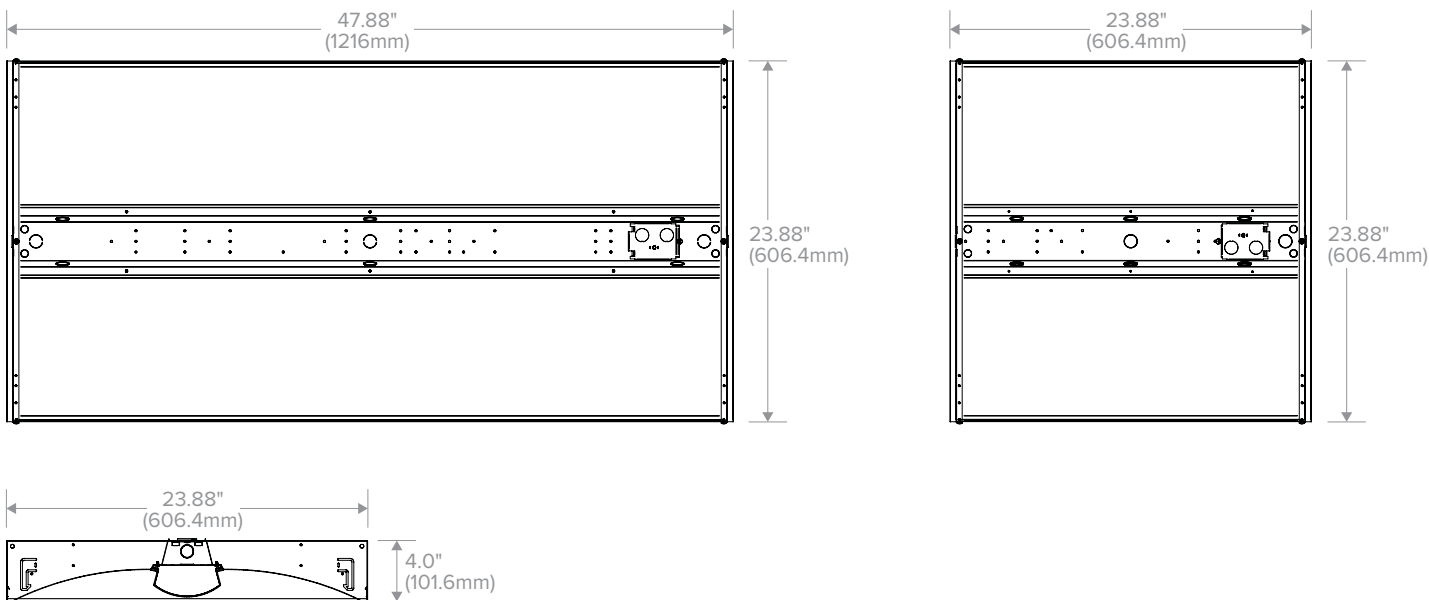

PHOTOMETRY

CCL22-3335


LUMINAIRE DATA

Test No.	1700782
Description	tradeSELECT® CCL Center Lens, Recessed Architectural 2x2 LED with linear prisms frosted acrylic lens
Delivered Lumens	3223
Watts	28.90
Efficacy	112
Mounting	Surface
Spacing Criterion	0° = 1.20 90° = 1.29

ZONAL LUMEN SUMMARY

Zone	Lumens	% Luminaire
0-30	822	25.5
0-40	1341	41.6
0-60	2381	73.9
0-90	3223	100.0
0-180	3223	100.0

POLAR GRAPH

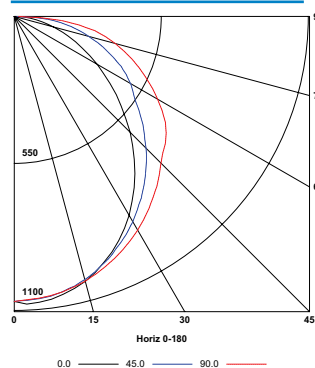

CCL24-5040

LUMINAIRE DATA

Test No.	17774
Description	tradeSELECT® CCL Center Lens, Recessed Architectural 2x4 LED with linear prisms frosted acrylic lens
Delivered Lumens	5191
Watts	43.90
Efficacy	118
Mounting	Surface
Spacing Criterion	0° = 1.20 90° = 1.29

ZONAL LUMEN SUMMARY

Zone	Lumens	% Luminaire
0-30	1313	25.3
0-40	2142	41.3
0-60	3806	73.3
0-90	5191	100.0
0-180	5191	100.0

POLAR GRAPH

