


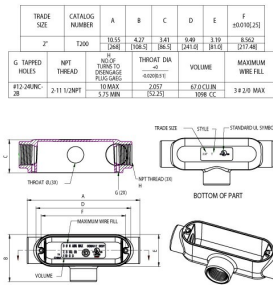

COMBO (RIGID/IMC OR EMT) BODIES AND ASSEMBLIES

Threaded Conduit Fittings: T Body Only 2" Rigid T Type Body

C13.1

Catalog #: T200

APPLICATIONS

For use with threaded Rigid/IMC conduit, for pulling access or to split a run into multiple directions.
N/A

PRODUCT FEATURES

Durable die cast aluminum construction
Premium powder coat finish
Combination head screw

CULUS

Listed

NEMA

NEMA 3R Rated

NEC

2014 NEC Compliant

GENERAL PRODUCT INFORMATION

Trade Size: 2"
Description Table: 2" Rigid T Type Body

PACKAGING

Package Type: Carton
Std. Pkg.: -
Ship Carton Qty.: 2
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 146
Ship Carton Length (in.): 11.22
Ship Carton Width (in.): 4.72
Ship Carton Height (in.): 8.27
Ctn Weight (Lbs.): 3.84
Pallet Qty: 288
UPC Number: 050169817056
I2of5: 50050169817051