




COMBO (RIGID/IMC OR EMT) BODIES AND ASSEMBLIES

Threaded Conduit Fittings: T Body Only
2-1/2" Rigid T Type Body

C13.1

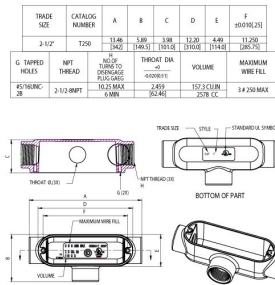

Catalog #: T250

APPLICATIONS

For use with threaded Rigid/IMC conduit, for pulling access or to split a run into multiple directions.
N/A

PRODUCT FEATURES

Durable die cast aluminum construction
Premium powder coat finish
Combination head screw

CULUS

Listed

NEMA

NEMA 3R Rated

NEC

2014 NEC Compliant

GENERAL PRODUCT INFORMATION

Trade Size: 2-1/2"
Description Table: 2-1/2" Rigid T Type Body

PACKAGING

Package Type:	Carton
Std. Pkg.:	-
Ship Carton Qty.:	1
Product UPC-A Labeled:	Yes
Weight (Lbs. Per/C):	300
Ship Carton Length (in.):	13.98
Ship Carton Width (in.):	5.59
Ship Carton Height (in.):	6.69
Ctn Weight (Lbs.):	3.53
Pallet Qty:	120
UPC Number:	050169817063
I2of5:	50050169817068