


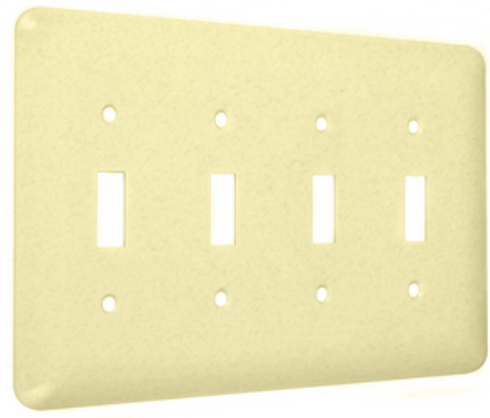

## 4-Gang Metal Wallplate, Maxi, 4-Toggle, Ivory Textured

By TayMac  
Catalog # [WRTI-TTTT](#)

4-Gang Metal Wallplate, Maxi, 4-Toggle, Ivory Textured



### Features

- Easily primed and painted to match or complement walls.
- Won't bow, crack or distort during installation.
- Premium North American powder coat.
- Includes screw(s) in matching finish.

### General

Color	Ivory
EU RoHS Indicator	Contact Manufacturer
Finish Type	Textured
Material	Metal
Number of Gang(s)	4-Gang
Size	Maxi
Style	4-Toggle
UPC	092326117050

### Dimensions

Dimensions	0.14 in x 8.23 in x 5.01 in
Height	5.01 in
Length	0.14 in
Weight	0.353 lb
Width	8.23 in

### Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

### Logistics

Carton Quantity	50
Minimum Pack Quantity	10
Pallet Quantity	1250

### Product Assets

- [Catalogs - RACO / TayMac / Bell Full Catalog](#)
- [Catalogs - Weatherproof Boxes, Covers & Lighting D1-D50](#)
- [Catalogs - Wallplates and HVAC E1-E26](#)
- [Literature - IN-USE COVERS CONDUIT BODIES WALLPLATES](#)
- [SDS - HCC SDS](#)
- [Terms and Conditions - HCC Terms & Conditions](#)



A Hubbell brand