


**Steel Stud Device Box, Gangable, 2 In. Deep, 10 Cu. In., With Raised Ground Screw, Msbs Bracket, 1-5/8 & 2-3/8 In. Stud Size, 1/2 In. Ko (25-Pack), 1102MSB**

By TradeSelect  
Catalog # [1102MSB](#)

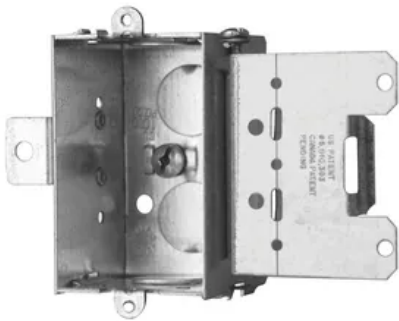

Steel Stud Device Box, Gangable, 2 in. Deep, 10 Cu. In., with Raised Ground Screw, MSBS Bracket, 1-5/8 & 2-3/8 in. Stud Size, 1/2 in. KO (25-Pack)

**Application**

Steel stud boxes are used in Commercial, Residential and Industrial construction.

**General**

Bracket Setback	0.4375
Bracket Type	MSBS, for Shallow Metal Stud
Catalog Number	1102MSB
Drawn or Welded	Welded
Gangable	Yes
Knockouts	4 x 1/2 in
Knockouts - Bottom	2 x 1/2in
Knockouts - End	2 x 1/2in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Switch Box, Box
UPC	626463000939

Wiring System                      Conduit

**Dimensions**

Actual Depth	2 in
Raised Ground	Yes
Weight	0.46 lb

**Certifications And Compliance**

Certified Listed	CSA
------------------	-----

**Logistics**

Carton Quantity	25
Pallet Quantity	1750

**Product Assets**

- [3D Product View - 1102MSB](#)
- [Specifications - 1102MSB Specification Sheet English](#)
- [Specifications - 1102MSB Specification Sheet French](#)