


**Steel Stud Device Box, Gangable, 2 In. Deep, 10 Cu. In., With Raised Ground Screw, Msbs Bracket, 1-5/8 & 2-3/8 In. Stud Size, Cable Pryouts Ends, Nmd90 And Ac90 (25-Pack), 1102MSBU**

By TradeSelect  
Catalog # [1102MSBU](#)

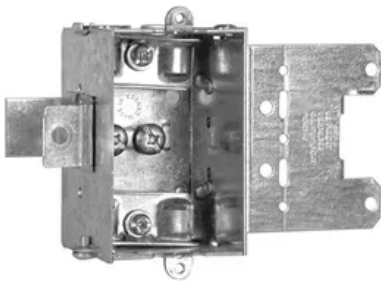

Steel Stud Device Box, Gangable, 2 in. Deep, 10 Cu. In., with Raised Ground Screw, MSBS Bracket, 1-5/8 & 2-3/8 in. Stud Size, Cable Pryouts Ends, NMD90 and AC90 (25-Pack)

**Application**

Steel stud boxes are used in Commercial, Residential and Industrial construction.

**General**

Bracket Setback	0.4375
Bracket Type	MSBS, for Shallow Metal Stud
Catalog Number	1102MSBU
Drawn or Welded	Welded
Ends Cable	4
Gangable	Yes
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Switch Box, Box
UPC	626463020746
Wiring System	Non-Metallic Sheathed (NMD)/Armoured Cable (AC) 14/2 8/3

**Dimensions**

Actual Depth	2 in
Raised Ground	Yes
Weight	0.51 lb

**Conductor Related**

Cable Entry	Universal Cable Clamps
-------------	------------------------

**Certifications And Compliance**

Certified Listed	CSA
------------------	-----

**Logistics**

Carton Quantity	25
Pallet Quantity	1750

**Product Assets**

- [3D Product View - 1102MSBU](#)
- [Sales Drawings - 1102MSBU](#)
- [Specifications - 1102MSBU Specification Sheet French](#)
- [Specifications - 1102MSBU Specification Sheet English](#)