


Steel Stud Device Box, Gangable, 2-1/2 In. Deep, 12.5 Cu. In., With Raised Ground Screw, Msb Metal Stud Bracket, 2-3/8 & 3-5/8 In. Stud Size, Cable Pryouts Ends, (25-Pack), 1104MSBU

By TradeSelect
Catalog # [1104MSBU](#)

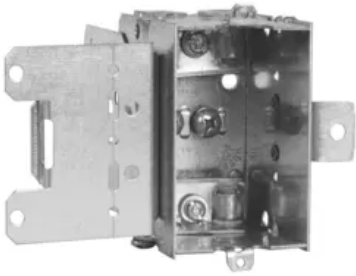

Steel Stud Device Box, Gangable, 2-1/2 in. Deep, 12.5 Cu. In., with Raised Ground Screw, MSB Metal Stud Bracket, 2-3/8 & 3-5/8 in. Stud Size, Cable Pryouts Ends, NMD90 and AC90 (25-Pack)

Application

Steel stud boxes are used in Commercial, Residential and Industrial construction.

General

Bracket Setback	0.4375
Bracket Type	MSB, for Steel Stud
Catalog Number	1104MSBU
Drawn or Welded	Welded
Ends Cable	4
Gangable	Yes
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Switch Box, Box
UPC	626463043486
Wiring System	Non-Metallic Sheathed (NMD)/Armoured Cable (AC) 14/2 8/3

Dimensions

Actual Depth	2 in
Raised Ground	Yes
Weight	0.6 lb

Conductor Related

Cable Entry	Universal Cable Clamps
-------------	------------------------

Certifications And Compliance

Certified Listed	CSA
------------------	-----

Logistics

Carton Quantity	25
Pallet Quantity	1050

Product Assets

- [3D Product View - 1104MSBU](#)
- [Sales Drawings - 1104MSBU](#)
- [Specifications - 1104MSBU Specification Sheet English](#)
- [Specifications - 1104MSBU Specification Sheet French](#)