


Steel Stud Device Box, 347V Box, Gangable, 2-1/2 In. Deep, 15.7 Cu. In., With Msb Metal Stud Bracket, 2-3/8 & 3-5/8 In. Stud Sizes, Raised Ground Screw, 1/2 In. Ko (25-Pack), 1204MSBHV

By TradeSelect
Catalog # [1204MSBHV](#)

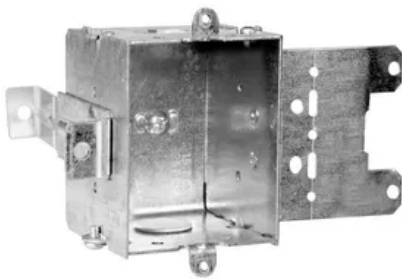

Steel Stud Device Box, 347V Box, Gangable, 2-1/2 in. Deep, 15.7 Cu. In., with MSB Metal Stud Bracket, 2-3/8 & 3-5/8 in. Stud Sizes, Raised ground screw, 1/2 in. KO (25-Pack)

Application

Steel stud boxes are used in Commercial, Residential and Industrial construction. 347 Volt boxes are used for the installation of 347 Volt switches for commercial and industrial lighting.

General

Bracket Setback	0.4375
Bracket Type	MSB, for Steel Stud
Catalog Number	1204MSBHV
Drawn or Welded	Welded
Gangable	Yes
Knockouts	2 x 1/2 in
Knockouts - End	2 x 1/2in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Box
UPC	626463001349
Wiring System	Conduit

Dimensions

Actual Depth	2.5 in
Raised Ground	Yes
Weight	0.7 lb

Certifications And Compliance

Certified Listed	CSA
Industry Standard(s)	CSA Certified

Logistics

Carton Quantity	25
Pallet Quantity	1050

Product Assets

- [3D Product View - 1204MSBHV](#)
- [Sales Drawings - 1204MSBHV](#)
- [Specifications - 1204MSBHV Specification Sheet French](#)
- [Specifications - 1204MSBHV Specification Sheet](#)