


Steel Stud Device Box, 2-1/2 In. Deep, 25 Cu. In., With Msb Metal Stud Bracket, 2-3/8 & 3-5/8 Stud Size, (20-Pack), 2104MSBKU2

By TradeSelect
Catalog # [2104MSBKU2](#)

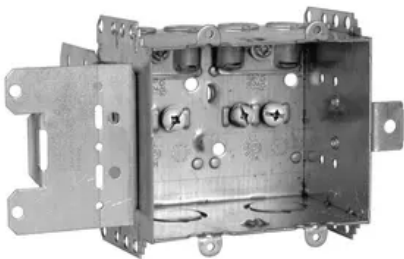

Steel Stud Device Box, 2-1/2 in. Deep, 25 Cu. In., with MSB Metal Stud Bracket, 2-3/8 & 3-5/8 Stud Size, with Concentric, 1/2 & 3/4 in. KO, Cable Pryouts Ends, Raised ground screw, NMD90 and AC90 (20-Pack)

Application

Steel stud boxes are used in Commercial, Residential and Industrial construction.

General

Bracket Setback	0.4375
Bracket Type	MSB, for Steel Stud
Catalog Number	2104MSBKU2
Drawn or Welded	Welded
Ends Cable	4
Gangable	No
Knockouts	2 x 1/2-3/4 in Combination
Knockouts - End	2 x 1/2-3/4in Combination
Material	Steel
Number of Gang(s)	2-Gang
Plaster Ears	No
Type	Switch Box, Box
UPC	626463040393
Wiring System	Non-Metallic Sheathed (NMD)/Armoured Cable (AC) 14/2 8/3

Dimensions

Actual Depth	2.5 in
Raised Ground	Yes
Weight	0.64 lb

Conductor Related

Cable Entry	Universal Cable Clamps
-------------	------------------------

Certifications And Compliance

Certified Listed	CSA
------------------	-----

Logistics

Carton Quantity	20
Pallet Quantity	720

Product Assets

- [3D Product View - 2104MSBKU2](#)
- [Sales Drawings - 2104MSBKU2](#)
- [Specifications - 2104MSBKU2 Specification Sheet English](#)
- [Specifications - 2104MSBKU2 Specification Sheet French](#)