


Steel Stud Device Box, Gangable, 3 In. Deep, 18 Cu. In., With Msb Metal Stud Bracket, 2-3/8 & 3-5/8 In. Stud Sizes, Raised Ground Screw, 1/2 In. Ko (20-Pack), 3004MSB

By TradeSelect
Catalog # [3004MSB](#)

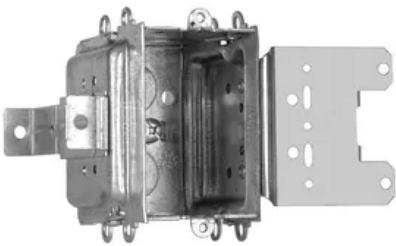

Steel Stud Device Box, Gangable, 3 in. Deep, 18 Cu. In., with MSB Metal Stud Bracket, 2-3/8 & 3-5/8 in. Stud Sizes, Raised ground screw, 1/2 in. KO (20-Pack)

Application

Steel stud boxes are used in Commercial, Residential and Industrial construction.

General

Bracket Setback	0.4375
Bracket Type	MSB, for Steel Stud
Catalog Number	3004MSB
Drawn or Welded	Welded
Gangable	Yes
Knockouts	4 x 1/2 in
Knockouts - Bottom	2 x 1/2in
Knockouts - End	2 x 1/2in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Switch Box, Box
UPC	626463000694
Wiring System	Conduit

Dimensions

Actual Depth	3 in
Raised Ground	Yes
Weight	0.68 lb

Certifications And Compliance

Certified Listed	CSA
Industry Standard(s)	CSA Certified

Logistics

Carton Quantity	20
Pallet Quantity	900

Product Assets

- [3D Product View - 3004MSB](#)
- [Sales Drawings - 3004MSB](#)
- [Specifications - 3004MSB Specification Sheet](#)
- [Specifications - 3004MSB Specification Sheet French](#)