


Steel Stud Device Box, Gangable, 3 In. Deep, 18 Cu. In., With Msb Metal Stud Bracket, 2-3/8 & 3-5/8 In. Stud Sizes, 1/2 In. Ko, Raised Ground Screw, (20-Pack), 3004MSB1

By TradeSelect
Catalog # [3004MSB1](#)

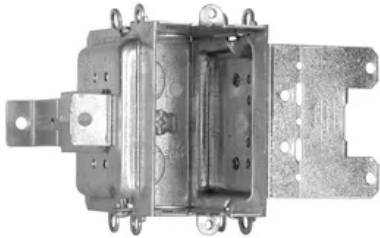

Steel Stud Device Box, Gangable, 3 in. Deep, 18 Cu. In., with MSB Metal Stud Bracket, 2-3/8 & 3-5/8 in. Stud Sizes, 1/2 in. KO, Raised ground screw, Brackets set back for two layers of 1/2 in. drywall (20-Pack)

Application

Steel stud boxes are used in Commercial, Residential and Industrial construction. Brackets set back for two layers of 1/2 in. drywall.

General

Bracket Setback	0.9375
Bracket Type	MSB, for Steel Stud
Catalog Number	3004MSB1
Drawn or Welded	Welded
Gangable	Yes
Knockouts	4 x 1/2 in
Knockouts - Bottom	2 x 1/2in
Knockouts - End	2 x 1/2in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Switch Box, Box
UPC	626463032107

Wiring System	Conduit
---------------	---------

Dimensions

Actual Depth	3 in
Raised Ground	Yes
Weight	0.68 lb

Certifications And Compliance

Certified Listed	CSA
Industry Standard(s)	CSA Certified

Logistics

Carton Quantity	20
Pallet Quantity	900

Product Assets

- [3D Product View - 3004MSB1](#)
- [Specifications - 3004MSB1 Specification Sheet](#)
- [Specifications - 3004MSB1 Specification Sheet French](#)