


Steel Stud Device Box, Gangable, 2-1/2 In. Deep, 16 Cu. In., With Msb Metal Stud Bracket, Bracket Set Back For Two Layers Of 1/2 In. Drywall, 2-3/8 & 3-5/8 In. (20-Pack), 3104MSB1

By TradeSelect
Catalog # [3104MSB1](#)

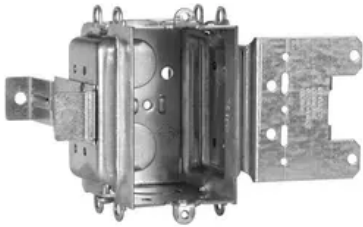

Steel Stud Device Box, Gangable, 2-1/2 in. Deep, 16 Cu. In., with MSB Metal Stud Bracket, Bracket set back for two layers of 1/2 in. Drywall, 2-3/8 & 3-5/8 in. Stud Sizes, Raised ground screw, with Concentric, 1/2 & 3/4 in., and 1/2 in. KO (20-Pack)

Application

Steel stud boxes are used in Commercial, Residential and Industrial construction. Brackets set back for two layers of 1/2 in. drywall.

General

Bracket Setback	0.9375
Bracket Type	MSB, for Steel Stud
Catalog Number	3104MSB1
Drawn or Welded	Welded
Gangable	Yes
Knockouts	2 x 1/2 in, 2 x 1/2-3/4 in Combination
Knockouts - Bottom	2 x 1/2in
Knockouts - End	2 x 1/2-3/4in Combination
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Switch Box, Box
UPC	626463032534

Wiring System

Conduit

Dimensions

Actual Depth	2.5 in
Raised Ground	Yes
Weight	0.65 lb

Certifications And Compliance

Certified Listed	CSA
Industry Standard(s)	CSA Certified

Logistics

Carton Quantity	20
Pallet Quantity	900

Product Assets

- [3D Product View - 3104MSB1](#)
- [Sales Drawings - 3104MSB1](#)
- [Specifications - 3104MSB1 Specification Sheet](#)
- [Specifications - 3104MSB1 Specification Sheet French](#)