


Steel Stud Device Box, Gangable, 2-1/2 In. Deep, 16 Cu. In., With Msb Metal Stud Bracket, 2-3/8 & 3-5/8 In. Stud Sizes, Cable Pryouts Ends, Raised Ground Screw, (25-Pack), 3104MSBU

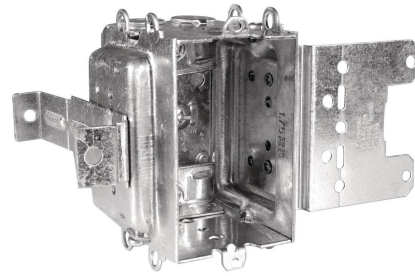

By TradeSelect
Catalog # [3104MSBU](#)

Steel Stud Device Box, Gangable, 2-1/2 in. Deep, 16 Cu. In., with MSB Metal Stud Bracket, 2-3/8 & 3-5/8 in. Stud Sizes, Cable Pryouts Ends, Raised ground screw, NMD90 and AC90 (25-Pack)

Application

Steel stud boxes are used in Commercial, Residential and Industrial construction.

Specifications

Certified Listed CSA

Conductor

Cable Entry Universal Cable Clamps

Configuration

Gangable Yes
Number of Gang(s) 1-Gang
Bracket Setback 0.4375
Bracket Type MSB, for Steel Stud

Dimensions

Weight 0.72 lb.
Actual Depth 2.5 in
Raised Ground Yes

General

Drawn or Welded Welded
Color Gray
Plaster Ears No
UPC 626463003237
Type Switch Box, Box
Wiring System Non-Metallic Sheathed (NMD)/
Armoured Cable (AC) 14/2 8/3
Ends Cable 4
Material Steel

Logistics

Pallet Quantity 1050
Carton Quantity 25