


**Steel Stud Device Box, Power / Communication Box, Gangable, 2-1/2 In. Deep, 12.5 Cu. In. / Gang, With Msb Metal Stud Bracket, 2-3/8 & 3-5/8 In. Stud Size, (20-Pack), 4204MSB**

By TradeSelect  
Catalog # [4204MSB](#)

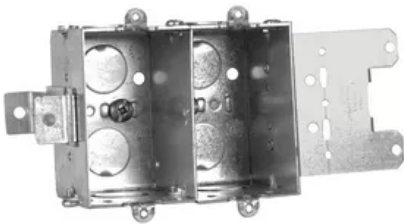

Steel Stud Device Box, Power / Communication Box, Gangable, 2-1/2 in. Deep, 12.5 Cu. In. / gang, with MSB Metal Stud Bracket, 2-3/8 & 3-5/8 in. Stud Size, Raised ground screw, with Concentric, 1/2 & 3/4 in., and 1/2 in. KO (20-Pack)

**Application**

Steel stud boxes are used in Commercial, Residential and Industrial construction.

**General**

Bracket Setback	0.4375
Bracket Type	MSB, for Steel Stud
Catalog Number	4204MSB
Drawn or Welded	Welded
Gangable	Yes
Knockouts	4 x 1/2 in, 4 x 1/2-3/4 in Combination
Knockouts - Bottom	4 x 1/2in
Knockouts - End	4 x 1/2-3/4in Combination
Material	Steel
Number of Gang(s)	2-Gang
Plaster Ears	No
Type	Communication Box
UPC	626463001530

Wiring System

Conduit

**Dimensions**

Actual Depth	2.5 in
Raised Ground	Yes
Weight	1.1 lb

**Certifications And Compliance**

Certified Listed	CSA
Industry Standard(s)	CSA Certified

**Logistics**

Carton Quantity	20
Pallet Quantity	840

**Product Assets**

- [3D Product View - 4204MSB](#)
- [Specifications - 4204MSB Specification Sheet](#)
- [Specifications - 4204MSB Specification Sheet French](#)