


4 In. Octagon Box, 1-1/2 In. Deep, 15 Cu. In.,
With Raised Ground Screw, 1/2 In. Ko,
Cable Pryouts, Ac90 (50-Pack),
54151LABAR

By TradeSelect
Catalog # 54151LABAR

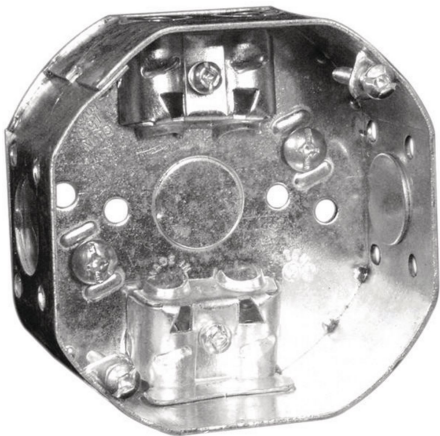

4 In. Octagon Box, 1-1/2 in. Deep, 15 Cu. In., with Raised Ground
Screw, 1/2 in. KO, Cable Pryouts, AC90 (50-Pack)

Application

Octagon boxes can be used in the installation of ceiling or wall
lighting fixtures. Extension rings provide a means for adding
additional cubic capacity.

Specifications

Certified Listed CSA

Conductor

Cable Entry AC clamp

Configuration

Gangable No
Number of Gang(s) 1-Gang
Knockouts 3 x 1/2 in
Bracket Type No Bracket

Dimensions

Weight 0.5 lb.
Knockouts - Bottom 1 x 1/2in
Knockouts - End 2 x 1/2in
Actual Depth 1.5 in
Raised Ground Yes

General

Drawn or Welded Welded
Color Gray
Plaster Ears No
UPC 626463002018
Type Octagonal Box, Box
Wiring System Armoured Cable (AC) 14/2 8/3
Ends Cable 8
Material Steel

Logistics

Pallet Quantity 2750
Carton Quantity 50