


54151LHB

By TradeSelect
Catalog Number [54151LHB](#)

4 In. Octagon Box, 1-1/2 in. Deep, 15 Cu. In., with Side Bracket, Raised Ground Screw, 1/2 in. KO, Cable Pryouts, NMD90 (50-Pack).

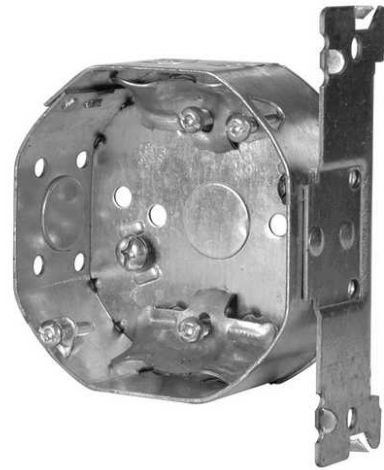

General

Application	Octagon boxes can be used in the installation of ceiling or wall lighting fixtures. Extension rings provide a means for adding additional cubic capacity.
Bracket Setback	0.4375
Bracket Type	B, Side Bracket
Color	<ul style="list-style-type: none"> • Gray • Gris
Drawn or Welded	Welded
Ends Cable	8
Gangable	No
Knockouts	2 x 1/2 in
Knockouts - Bottom	1 x 1/2in
Knockouts - End	1 x 1/2in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Sub Brand	tradeSELECT
Type	Octagonal Box, Box
UPC	626463021118
Wiring System	Non-Metallic Sheathed (NMD) 14/2 8/3

Dimensions

Actual Depth	1.5 in
Raised Ground	Yes
Weight	0.55 lb

Conductor Related

Cable Entry	NMD Clamp
-------------	-----------

Certifications and Compliance

Certified Listed	CSA
Industry Standard(s)	CSA Certified

Logistics

Carton Quantity	50
Pallet Quantity	2250

Product Assets

[3D Product View](#)

