


## 54171LHB

By TradeSelect  
Catalog Number [54171LHB](#)

4 In. Octagon Box, 2-1/8 in. Deep, 21 Cu. In., with Side Bracket, Raised Ground Screw, 1/2 in. KO, Cable Pryouts, NMD90 (50-Pack).

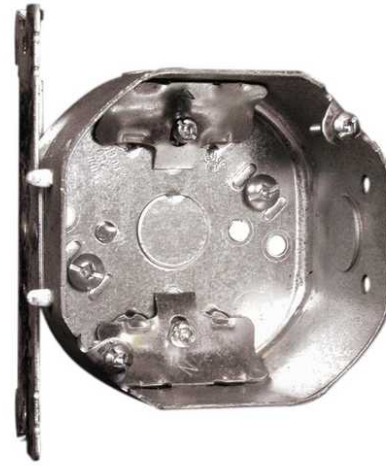

### General

Application	Octagon boxes can be used in the installation of ceiling or wall lighting fixtures. Extension rings provide a means for adding additional cubic capacity.
Bracket Setback	0.4375
Bracket Type	B, Side Bracket
Color	<ul style="list-style-type: none"> <li>• Gray</li> <li>• Gris</li> </ul>
Drawn or Welded	Drawn
Ends Cable	8
Gangable	No
Knockouts	2 x 1/2 in
Knockouts - Bottom	1 x 1/2in
Knockouts - End	1 x 1/2in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Sub Brand	tradeSELECT
Type	Octagonal Box, Box
UPC	626463021125
Wiring System	Non-Metallic Sheathed (NMD) 14/2 8/3

### Dimensions

Actual Depth	2.125 in
Raised Ground	Yes
Weight	0.65 lb

### Conductor Related

Cable Entry	NMD Clamp
-------------	-----------

### Certifications and Compliance

Certified Listed	CSA
Industry Standard(s)	CSA Certified

### Logistics

Carton Quantity	50
Pallet Quantity	1400

