

2 Pole, 100 Amp Relay

By Trinetics
Catalog # [31191101](#)


2-pole, 120/240V, Norm Open; Form A air contact, 100A; Load protection: Fuse; Coil voltage: 120V; Control circuit source: Line; Photocell provision: Mounted Receptacle; Control circuit arrester: Spark Gap; in a weather proof case. 3/8" Ground Stud with hardware; Waterproof connectors for LINE & LOAD cable entry, 4 each; Grommet for NEUTRAL cable entry

Features

The MR Series is the foundation of the Trinetics product line of multiple relay lighting controls. MR relays feature a time-proven electromagnetic design that provides high compression, low audible noise and minimum eddy current heating. For customers in need of heavy duty construction and long-term performance, the MR Series is built for years of trouble-free service in the most challenging environments.

General

Catalog Number	31191101
Circuit Protection	Fuse
Contact	Air
Contact Configuration	N.O.
Material	Cast Aluminum
Number Of Poles	2
Size	17-1/4 x 11-7/16 x 8-1/4
UPC	096359593836

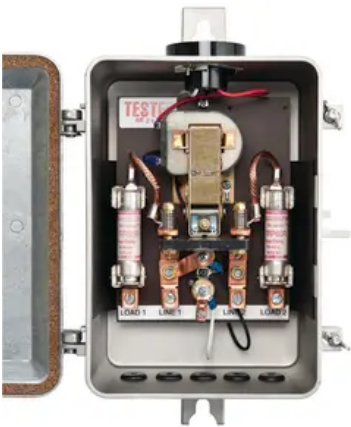

Dimensions

Dimensions	17.25 in x 11.43 in x 8.25 in
Height	8.25 in
Length	17.25 in
Weight	24 lb
Width	11.43 in

Electrical Ratings

Amperage Rating	100 A
Coil Voltage	120V
Voltage Rating	120/240 V

Product Assets

- [Catalogs - Lighting Control Relays](#)
- [Sales Drawings - Relay Assembly MR-YG Spec 6314 \(31191101\)](#)
- [Specifications - 31191101](#)