

1 Pole, 60 Amp Relay

By Trinetics  
Catalog # [MR-HHFY](#)


1 pole with 2 loads, 480V, Norm Open; Form A air contact, 60A;  
Load protection: Fuse; Line/load circuit arresters: MOV; Coil  
voltage: 120V; Control circuit source: Internal Transformer;  
Photocell provision: Mounted Receptacle; HOA: Internal ; in a  
weather proof case.

Features

The MR Series is the foundation of the Trinetics product line of multiple relay lighting controls. MR relays feature a time-proven electromagnetic design that provides high compression, low audible noise and minimum eddy current heating. For customers in need of heavy duty construction and long-term performance, the MR Series is built for years of trouble-free service in the most challenging environments.

General

Catalog Number	MR-HHFY
Circuit Protection	Fuse
Contact	Air

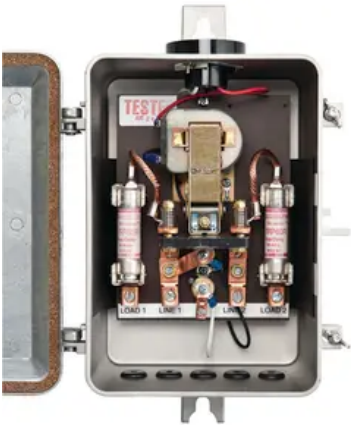

Contact Configuration	N.O.
Material	Cast Aluminum
Number Of Poles	1
Size	17-1/4 x 11-7/16 x 8-1/4

Electrical Ratings

Amperage Rating	60 A
Coil Voltage	120V
Voltage Rating	480 V

Product Assets

[Sales Drawings - Relay Assembly MR-HHFY Spec 6883 \(33201300\)](#)  
[Specifications - MRHHFY](#)