

HUBBELL Power Systems

2 Pole, 60 Amp Relay

By Trinetics

Catalog # [MR-UGX SPEC 6384](#)


2-pole, 240V LINE/LOAD, Norm Open; Form A air contact, 60A; Load protection: Fuse; Coil voltage: 120V; Control circuit source: Separate 120V source; Photocell provision: Mounted Receptacle; Control circuit arrester: Spark Gap; in a weather proof case.

Features

The MR Series is the foundation of the Trinetics product line of multiple relay lighting controls. MR relays feature a time-proven electromagnetic design that provides high compression, low audible noise and minimum eddy current heating. For customers in need of heavy duty construction and long-term performance, the MR Series is built for years of trouble-free service in the most challenging environments.

General

Catalog Number	MR-UGX SPEC 6384
Circuit Protection	Fuse
Contact	Air

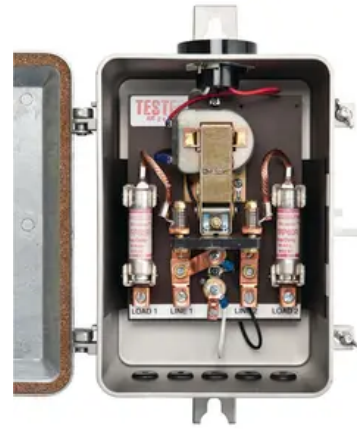

Contact Configuration	N.O.
Material	Cast Aluminum
Number Of Poles	2
Size	14 3/16 x 9 x 5 1/8
UPC	096359593768

Electrical Ratings

Amperage Rating	60 A
Coil Voltage	120V
Voltage Rating	120/240 V

Product Assets

[Sales Drawings - Relay Assembly MR-UGX Spec 6384 \(31131509\)](#)
[Specifications - MR-UGX SPEC 6384](#)