


HUBBELL Power Systems

2 Pole, 60 Amp Relay

By Trinetics
Catalog # [MR-UNX S](#)

2-pole, 120/240V, Norm Open; Form A air contact, 60A; Load protection: Fuse; Coil voltage: 120V; Control circuit source: Line; Photocell provision: Mounted Receptacle; HOA: Internal ; Control circuit arrester: Spark Gap; in a weather proof case. Fuses not included with unit, tamper proof bar for cover nuts

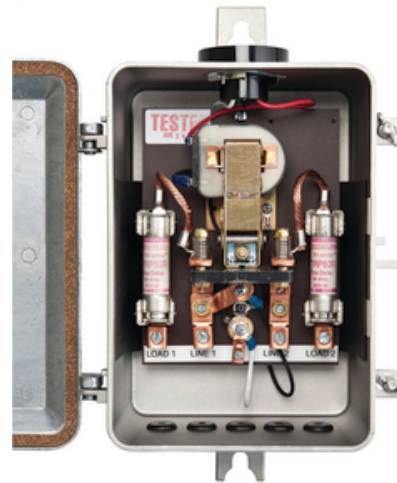

Features

The MR Series is the foundation of the Trinetics product line of multiple relay lighting controls. MR relays feature a time-proven electromagnetic design that provides high compression, low audible noise and minimum eddy current heating. For customers in need of heavy duty construction and long-term performance, the MR Series is built for years of trouble-free service in the most challenging environments.

General

Catalog Number	MR-UNX S
Circuit Protection	Fuse
Contact	Air
Contact Configuration	N.O.
Material	Cast Aluminum
Number Of Poles	2
Size	17-1/4 x 11-7/16 x 8-1/4
UPC	096359637165

Electrical Ratings

Amperage Rating	60 A
Coil Voltage	120V
Voltage Rating	120/240 V

Product Assets

[Sales Drawings - Relay Assembly MR-UNX Spec 6924 \(31197202\)](#)