

2 Pole, 30 Amp Relay

By Trinetics
Catalog # [MR-WI](#)


2-pole, 120/240V, Norm Open; Form A air contact, 30A; Coil voltage: 120V; Control circuit source: Line; Photocell provision: Mounted Receptacle; Control circuit arrester: Spark Gap; in a weather proof case.

Features

The MR Series is the foundation of the Trinetics product line of multiple relay lighting controls. MR relays feature a time-proven electromagnetic design that provides high compression, low audible noise and minimum eddy current heating. For customers in need of heavy duty construction and long-term performance, the MR Series is built for years of trouble-free service in the most challenging environments.

General

Catalog Number	MR-WI
Circuit Protection	None
Contact	Air

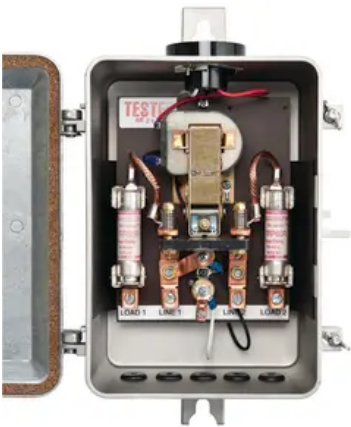

Contact Configuration	N.O.
Material	Phenolic
Number Of Poles	2
Size	9 x 3 15/16 x 4 15/16
UPC	096359594031

Electrical Ratings

Amperage Rating	30 A
Coil Voltage	120V
Voltage Rating	120/240 V

Product Assets

[Sales Drawings - Relay Assembly MR-WI Spec 6400 \(31152500\)](#)
[Specifications - MRWI](#)