


2 Pole, 60 Amp Relay

By Trinetics
Catalog # [MR-ZDK](#)

2-pole, 240/480V, Norm Open; Form A contact, 60A; Load protection: Fuse; Line/load circuit arresters: MOV; Coil voltage: 120V; Control circuit source: Internal Transformer; Photocell provision: Mounted Receptacle; Control circuit arrester: Spark Gap; in a weather proof case.

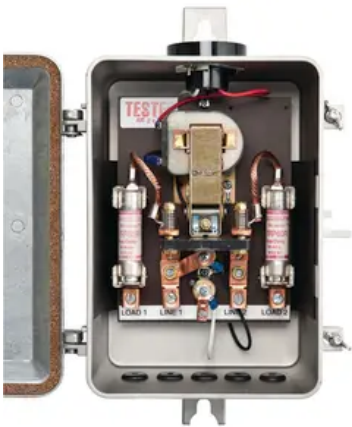

Features

The MR Series is the foundation of the Trinetics product line of multiple relay lighting controls. MR relays feature a time-proven electromagnetic design that provides high compression, low audible noise and minimum eddy current heating. For customers in need of heavy duty construction and long-term performance, the MR Series is built for years of trouble-free service in the most challenging environments.

General

Catalog Number	MR-ZDK
Circuit Protection	Fuse
Contact	Air
Contact Configuration	N.O.
Material	Cast Aluminum
Number Of Poles	2
Size	17-1/4 x 11-7/16 x 8-1/4
UPC	096359636724

Dimensions

Dimensions	17.25 in x 11.43 in x 8.25 in
Height	8.25 in
Length	17.25 in
Weight	25.4 lb
Width	11.43 in

Electrical Ratings

Amperage Rating	60 A
Coil Voltage	120V
Voltage Rating	240/480 V

Product Assets

[Catalogs - Lighting Control Relays](#)
[Sales Drawings - Relay Assembly MR-ZDK Spec 6916 \(33216700\)](#)
[Specifications - MRZDK](#)