

1 Pole, 30 Amp Relay

By Trinetics  
Catalog # [RLY-XG](#)


1-pole, 120V, air contact, 30A; Load protection: Fuse; Coil voltage: 120V; Control circuit source: Line; Photocell provision: Mounted Receptacle; Control circuit arrester: Spark Gap; in a weather proof case.

Features

The RLY Series was developed for lighting system designers in need of an inexpensive control relay that outperforms throw-away type units that are sealed or difficult to repair. The reputation of the Trinetics line proves durability and maintainability are essential to cost-efficient lighting relays. The RLY Series offers superior service life, durability and maintainability at a competitive purchase price.

General

Catalog Number	RLY-XG
Circuit Protection	Fuse
Contact	Air
Contact Configuration	N.C.
Material	Lexan
Number Of Poles	1
Size	9 x 6 13/16 x 5 1/16
UPC	096359592723

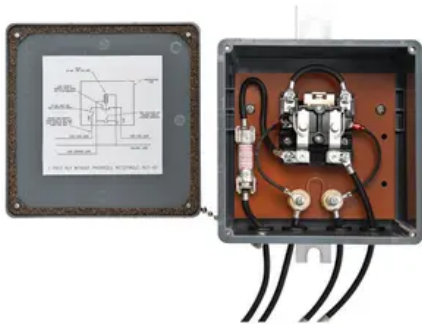

Dimensions

Dimensions	9 in x 6.812 in x 5.06 in
Height	5.06 in
Length	9 in
Weight	8 lb
Width	6.812 in

Electrical Ratings

Amperage Rating	30 A
Coil Voltage	120V
Voltage Rating	120 V

Product Assets

- [Catalogs - Lighting Control Relays](#)
- [Sales Drawings - Relay Assembly RLY-XG Spec 6785 \(33133000\)](#)
- [Specifications - RLYXG](#)