


# tradeSELECT® BANANA BOX™

## Non-metallic Vapor Barrier Box, 3-Gang, 52.6 Cu. In., with side bracket

By tradeSELECT  
Catalogue # 2023FBAR

Non-Metallic Boxes, Devices Boxes, For use with non-metallic sheathed cable, Flanged with Vapour Barrier, 52.6 Cu. In., 3-gang with side bracket, 1/2 In. Setback, 12 Cable Clamp (25-Pack)

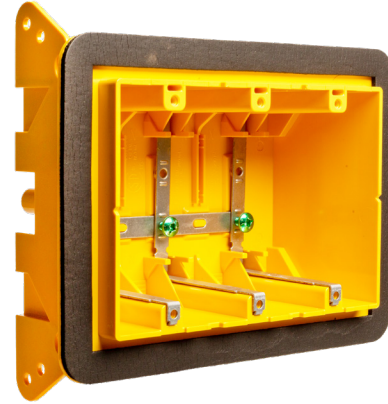

### Feature

- Energy efficient vapour barrier flange provides superior energy savings, reduces air leakage through exterior walls and eliminates the need for separate vapour / air barriers
- Partition slots for optional low voltage barrier sold separately
- Center marks for quick height positioning, nail / screw guides as well as inside and external mounting holes for faster and more flexible installation.
- Preset flange at 1/2" for fast positioning
- Engravings at 5/8" and 1" ensure box placement in accurate and consistent depths, while reducing the installation time
- Breakable tabs, perfect for double drywall installation.
- Superior cubic capacity - Additional volume makes termination easier and is excellent for deeper body devices
- Oversized nailing / screw bracket for better reach to mount on stud or joint
- High hammer impact resistant when nailing
- Lightweight
- Bright yellow color helps to locate wires in low light levels

### Application

Accommodates wiring devices such as switches and receptacles

### General

Bracket Setback	0.50"
Colour	Yellow
Fire Resistance	Yes
Material	Thermoplastic Resin
Number of Gang(s)	3-Gang
Type	Non-Metallic Box
UPC	805035054444
Wiring System	Nonmetallic Sheathed Cable

### Dimensions

Cubic Capacity	52.6 Cu.In. (862mL)
Depth	2.74 in
Height	3.90 in
Weight	0.404 lb
Width	5.87 in

### Certifications and Compliance

Industry Standard(s)	cCSAus Certified
CSA Cable Range NMD-90	14/2, 14/3, 12/3, 12/2 or 10/2
UL CABLE RANGE NM-B	10/2

### Logistics

Carton Quantity	25
Pallet Quantity	750

### Product Assets

3D Product View



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved. Hubbell and the Hubbell logo are registered trademarks or trademarks of Hubbell Inc. All other trademarks are the property of their respective owners.

Hubbell Canada | 870 Brock Rd S, Pickering, ON L1W 1Z8  
hubbell.ca | 800-465-7051

tradeSELECT-2023FBAR-Spec-Sheet-08-2024-CanEN-V2