




Compression Stirrup

by ANDERSON
Catalog ID: VCLS3018

Aluminum Overhead Compression Stirrup (Figure 1)

- For use with VersaCrimp tools only (VC6).

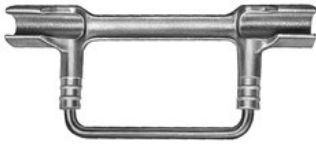

* Representative image

Product Details

General

Bolt Installation Torque (Recommended)	0 ft-lbs
Compression Tool Type	VC6 (all)
Material - Body	Aluminum Alloy
Material - Stirrup	Copper
Plating	No
Type	Stirrups
UPC	096359336884

Dimensions

Copper Loop Size	0.258 in
Diameter - Stirrup Nominal Wire	#2 Solid
Weight	0.118 lb
Width - Main Contact	4 in

Conductor Related

Conductor Diameter - Maximum	0.325 in
Conductor Diameter - Minimum	0.162 in
Conductor Diameter Range	0.162 - 0.325

Logistics

Carton Quantity	40 EA
Packaging Type	Bag

For further technical assistance, please contact us

Domestic Customer Service

Hubbell Power Systems
210 N. Allen Centralia, MO 65240 USA
Phone: (573) 682-5521
Fax: (573) 682-8475
Email: hpscs@hubbell.com

International Customer Service

Phone: +1-573-682-5521
Fax: +1-573-682-8516
Email: hpsintlcs@hubbell.com