




Wiring Device-Kellems

Audio/Video Connector, D-Sub, 15-Pin VGA, ScrewTerminal, 10 Pack

By Hubbell Wiring Device-Kellems
Catalog # [15ST10](#)

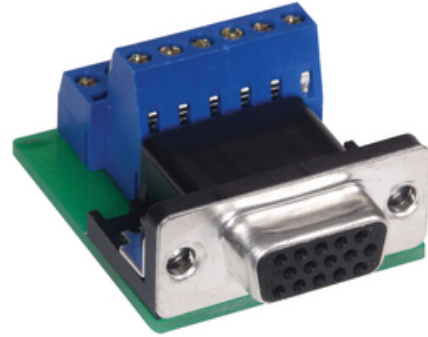

Audio/Video Connector, D-Sub, 15-Pin VGA, ScrewTerminal, 10 Pack

General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION VGA Analog Video Connections
Material - Mounting Hardware	Snap-On- Snap-Fit
Style	HD, 15-Pin
Temperature Rating	Per TIA
Type	Screw Term
UPC	662620843735

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Screw Terminals
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

Logistics

Carton Quantity	25
-----------------	----

Product Assets

- [Catalog Page - Wiring_Catalog_Z6_CatPage](#)
- [Catalogs - Wiring Full Catalog](#)
- [Warranty - Industrial & Commercial Products](#)

Related Products

- [SF15ST - 15 Pin D-Sub SVGA Connector, Screw Terminal](#)
- [9ST10 - Audio/Video Connector, D-Sub, Female 9- Pin, Screw Terminal, 10 Pack](#)
- [9GC10 - Adapter, Gender Changer, 9-Pin, 10 Pack](#)
- [15GC10 - Audio/Video Connector, D-Sub, 15-Pin, Gender Changer Bulk Connector, 10 Pack](#)
- [15901 - Audio/Video Connector, D-Sub, 15-Pin, Female to Female, 90 Degree, Single Pack](#)



A proud member of the Hubbell Family.