

Heavy Duty Products, Insulgrip Pin and Sleeve Devices, Industrial Grade, Accessories, 55 Degree Angle Adapter For 60 and 100A Mounting Screw Included

By Hubbell Wiring Device-Kellems  
Catalog # [AA6010055](#)

Heavy Duty Products, Insulgrip Pin and Sleeve Devices, Industrial Grade, Accessories, 55 Degree Angle Adapter For 60 and 100A Mounting Screws Included, Gray Cast Aluminum

Features


- Industrial Grade
- Accessories
- 55 Degree Angle Adapter For 60 and 100A Mounting Screw Included

Application

Metallic

General

Catalog Number	AA6010055
Color	Gray
Construction	Cast
EU RoHS Indicator	No
Item Type	Mounting Box
Knockouts	None
Material	Aluminum
Material - Mounting Hardware	Mounting Screws
Number Of Outlets	Accepts 1-Device
OEM Brand Name	Hubbell Wiring Device-Kellems
Series	Back Boxes and Adapters
Specifications	Accessory Item - Angle Adapter
Style	55 Degree

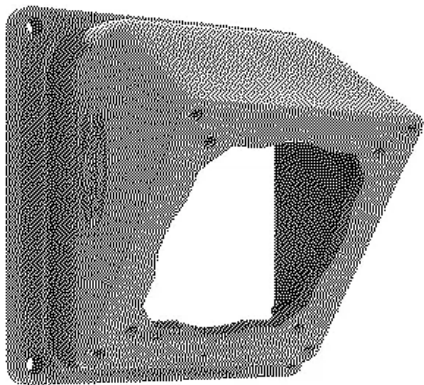

Temperature Range	Limited By Device
Type	Angled Adapter
UPC	783585810065

Dimensions

Display Size	For 60, 63, 100 and 125A Devices
--------------	----------------------------------

Logistics

Carton Quantity	1
Pallet Quantity	216

Product Assets

- [Catalog Page - WDK G-28 Catalog Page](#)
- [Catalog Page - WDK G-35 Catalog Page](#)
- [Catalogs - WDK Catalog Full 2024](#)
- [Engineering Drawing - AA6010055 AutoCAD Drawing](#)
- [Installation Manuals - WIRING\\_PD2332\\_INSTALLINST](#)
- [Literature - IEC Pin & Sleeve Devices](#)
- [Literature - PULP & PAPER SOLUTIONS](#)
- [Literature - Pulp & Paper Solutions](#)
- [Literature - Dual-Certified IEC Pin & Sleeve Devices](#)
- [Sales Drawings - WDK\\_AA6010055\\_DRAWING\\_PDF](#)
- [Specifications - Wiring AA6010055 Specification Sheet](#)
- [Warranty - Industrial & Commercial Products](#)

