




Wiring Device-Kellems

C360C4SLT34

By Hubbell Wiring Device-Kellems
Catalog # [C360C4SLT34](#)

Heavy Duty Products, IEC Pin and Sleeve Devices, Hubbell-PRO, Female, Connector Body, 60 A 125 VAC, 2-POLE 3-WIRE, Yellow, Splash Proof

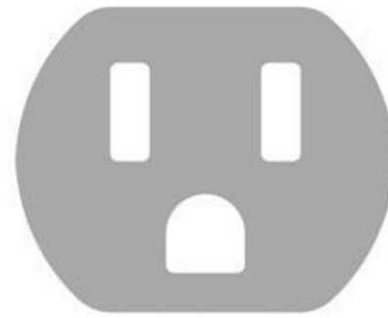

Oh No!
IMAGE COMING SOON

Features

- IP44 environmental ratings
- Impact and corrosion resistant insulated non-metallic housing
- Sequential contact engagement to prevent a momentary over-voltage
- External strain relief
- Glandless water ingress protection

General

Color	Yellow
Number Of Poles	2-POLE
Series	Hubbell-PRO
Style	Standard Device
Type	Splash Proof Liquidtight Connector
UPC	783585713885

Electrical Ratings

Current / Amperage Rating	60 A
Voltage Rating Description	125 VAC

Conductor Related

Number Of Wires	3-WIRE
-----------------	--------

Logistics

Carton Quantity	5
-----------------	---

Product Assets

[Sales Drawings - Sales Drawing M-14500](#)

Related Products

[C360C4SA - Heavy Duty Products, IEC Pin and Sleeve Devices, Hubbell-PRO, Female, Connector Body, 60 A 125 VAC, 2-POLE 3-WIRE, Yellow, Splash Proof](#)

[FW60100 - Heavy Duty Products, IEC Pin and Sleeve Devices, Industrial Grade, Back Box, For 60A and 100A 1 1/2" NPT Hub, 4 Way Angled, Mounting Screws Included](#)

[PC3430 - Heavy Duty Products, IEC Pin and Sleeve Devices, Industrial Grade, Accessories, Male Closure Cap, For 30A 3 and 4-Wire Gray Non-Metallic](#)

[C360P4SA - Heavy Duty Products, IEC Pin and Sleeve Devices, Hubbell-PRO, Male, Plug, 60 A 125 VAC, 2-POLE 3-WIRE, Yellow, Splash Proof](#)

[BB60N - Heavy Duty Products, IEC Pin and Sleeve Devices, Industrial Grade, Back Box, For 60A 1 1/4" NPT Hub, Angled, Mounting Screws Included Non-Metallic](#)



A proud member of the Hubbell Family.