




Wiring Device-Kellems

C560C6WLT34

By Hubbell Wiring Device-Kellems
Catalog # [C560C6WLT34](#)

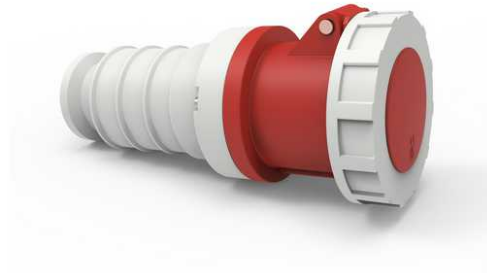

Heavy Duty Products, IEC Pin and Sleeve Devices, Hubbell-PRO, Female, Connector Body, 60/63 A 200-415 VAC, 4-POLE 5-WIRE, Red, Watertight

Features

- IP67 environmental ratings
- Impact and corrosion resistant insulated non-metallic housing
- Sequential contact engagement to prevent a momentary over-voltage
- External strain relief
- Glandless water ingress protection

General

Color	Red
Number Of Poles	4-POLE
Series	Hubbell-PRO
Style	Standard Device
Type	Watertight Liquidtight Connector Body
UPC	783585714219

Electrical Ratings

Current / Amperage Rating	60/63 A
Voltage Rating Description	200-415 VAC

Conductor Related

Number Of Wires	5-WIRE
-----------------	--------

Logistics

Carton Quantity	5
-----------------	---

Product Assets

[Sales Drawings - WDK_M-14501_SalesDrawing](#)

Related Products

- [C560P6WA - Heavy Duty Products, IEC Pin and Sleeve Devices, Hubbell-PRO, Male, Plug, 60/63 A 200-415 VAC, 4-POLE 5-WIRE, Red, Watertight](#)
- [C560C6WA - Heavy Duty Products, IEC Pin and Sleeve Devices, Hubbell-PRO, Female, Connector Body, 60/63 A 200-415 VAC, 4-POLE 5-WIRE, Red, Watertight](#)
- [C560R6WA - Heavy Duty Products, IEC Pin and Sleeve Devices, Hubbell-PRO, Female, Receptacle, 60/63 A 200-415 VAC, 4-POLE 5-WIRE, Red, Watertight](#)
- [FW60100 - Heavy Duty Products, IEC Pin and Sleeve Devices, Industrial Grade, Back Box, For 60A and 100A 1 1/2" NPT Hub, 4 Way Angled, Mounting Screws Included](#)
- [C560B6WA - Heavy Duty Products, IEC Pin and Sleeve Devices, Hubbell-PRO, Male, Inlet, 60/63 A 200-415 VAC, 4-POLE 5-WIRE, Red, Watertight](#)



A proud member of the Hubbell Family.