




Wiring Device-Kellems

Fire-Classified Kit for CFB11G Series for Rectangular Covers, 2 or 3 Hour Fire Classified Floor Rating

By Hubbell Wiring Device-Kellems
Catalog # [CFB11G6FRK](#)

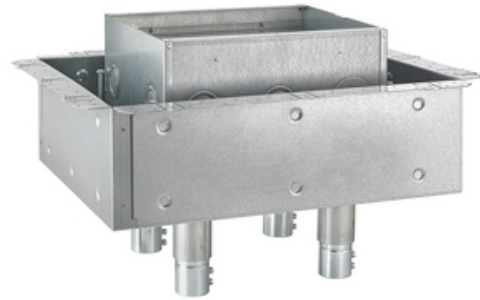

Concrete Concrete, Access, Wood Floorboxes, Recessed, Fire-Classified Kit for CFB11G Series for Rectangular Covers, 2 or 3 Hour Fire Classified Floor Rating

Features

- Fire-Classified Kit for Use with 11-Gang CFB11G6 Floorbox
- For Concrete Pours from 3¼" up to 5½" Above Upper Most Portion of Decking
- Preserves 2 or 3 hour Fire Classified Floor Rating

Application

For Use in Concrete Floors

General

Accessory Type	Fire Classified Kit
Application - For Use On	Concrete
Color	Metallic
Construction	Fabricated
EU RoHS Indicator	Contact Manufacturer
Material	Composite
Mounting Method	Steel Decking
Number of Gang(s)	11-Gang
Series	Recessed Rectangular - CFB Series
Size	11-Gang
Sub Brand	Recessed Concrete Floor Boxes
Type	Fire-Classified Floor Box Kit
UPC	783585545783

Dimensions

Dimensions	20.68 in x 17.18 in x 6.5 in
Height	6.5 in
Length	20.68 in
Width	17.18 in

Conductor Related

Cable Entry Through Cover

Certifications and Compliance

Industry Standard(s)

- UL/CSA
- UL514

Product Assets

[BIM - Electrical_Equipment-Floor_Box-Hubbell_Wiring-11_Gang-CFB11G_Series](#)
[Catalog Page - Wiring P-32 Catalog page](#)
[Catalogs - Wiring Full Catalog](#)
[Engineering Drawing - CFB11G6FRK AutoCAD Drawing](#)
[Installation Manuals - WIRING_CFB11G6FRK_INSTALLINST](#)
[Literature - Fire-Classified Floor Box Solutions](#)
[Sales Drawings - WDK_CFB11G6FRK_DRAWING_PDF](#)
[Warranty - Industrial & Commercial Products](#)

Related Products

[CFB11G6 - 11-Gang CFB Series Box for Rectangular Cover, 6.08" Minumum Depth of Pour](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
WDK-CFB11G6FRK-SPEC-EN | REV 5/2023