




Wiring Device-Kellems

Fire-Classified Kit for CFB7G Series for Rectangular Covers, 2 or 3 Hour Fire Classified Floor Rating

By Hubbell Wiring Device-Kellems
Catalog # [CFB7G6FRK](#)

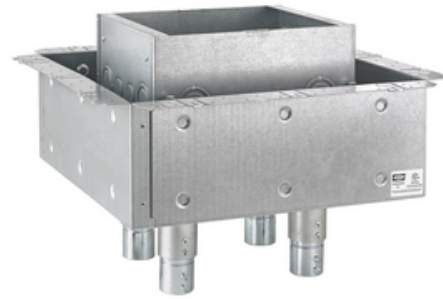

Concrete Floorboxes, Recessed, Fire-Classified Kit for CFB7G Series for Rectangular Covers, 2 or 3 Hour Fire Classified Floor Rating

Features

- Fire-Classified Kit for Use with 7-Gang CFB7G6 Floorbox
- For Concrete Pours from 3¼" up to 5½" Above Upper Most Portion of Decking
- Preserves 2 or 3 hour Fire Classified Floor Rating

Application

For Use in Concrete Floors

General

Accessory Type	Fire Classified Kit
Application - For Use On	Concrete
Color	Metallic
Construction	Fabricated
EU RoHS Indicator	Contact Manufacturer
Material	Composite
Mounting Method	Steel Decking
Number of Gang(s)	7-Gang
Series	Recessed Rectangular - CFB Series
Size	7-Gang
Sub Brand	Recessed Concrete Floor Boxes
Type	Fire-Classified Floor Box Kit
UPC	783585545776

Dimensions

Dimensions	17.18 in x 17.18 in x 6.5 in
Height	6.5 in
Length	17.18 in
Width	17.18 in

Conductor Related

Cable Entry (1) Egress Door

Certifications and Compliance

Industry Standard(s)

- UL/CSA
- UL514

Product Assets

- [BIM - Electrical_Equipment-Floor_Box-Hubbell_Wiring-7_Gang-CFB7G_Series](#)
- [Catalog Page - Wiring P-32 Catalog page](#)
- [Catalogs - Wiring Full Catalog](#)
- [Engineering Drawing - CFB7G6FRK AutoCAD Drawing](#)
- [Installation Manuals - WIRING_CFB7G6FRK_INSTALLINST](#)
- [Literature - Fire-Classified Floor Box Solutions](#)
- [Sales Drawings - WDK_CFB7G6FRK_DRAWING_PDF](#)
- [Warranty - Industrial & Commercial Products](#)

Related Products

[CFB7G6 - 7-Gang CFB Series Box for Rectangular Covers, 6.08" Minimum Depth of Pour](#)



A proud member of the Hubbell Family.