




Floor Boxes, CFB Series, 8.00" Collar,.25"-.50"

By Hubbell Wiring Device-Kellems
Catalog # [CFB8RCVRR2](#)

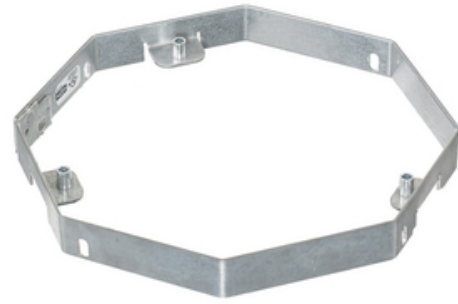

Floor Boxes, CFB Series, 8.00" Collar,.25"-.50"

General

Application - For Use On	Concrete
Cover Shape	Round
EU RoHS Indicator	Contact Manufacturer
Material	Pre Galvanized Steel
Mounting Method	Mounts to Box
UPC	783585447506

Conductor Related

Cable Entry	Through Cover
-------------	---------------

Product Assets

[Catalog Page - Wiring P-11 Catalog page](#)
[Catalogs - Wiring Full Catalog](#)
[Engineering Drawing - CFB8RCVRR2 AutoCAD Drawing](#)
[Literature - Hubbell SystemOne Recessed Floor Boxes](#)
[Sales Drawings - WDK_CFB8RCVRR2_DRAWING_PDF](#)
[Warranty - Industrial & Commercial Products](#)
[Video - SystemOne Recessed Floor Boxes](#)

Related Products

[CFB4G25RCR - 4-Gang CFB Series Box for Round Covers, 3.25" Minimum Depth of Pour, Corrosion Resistant Paint](#)
[CFB4G25R - 4-Gang CFB Series Box for Round Covers, 3.25" Minimum Depth of Pour](#)
[CFB6G30R - 6-Gang CFB Series Box for Round Covers, 3.75" Minimum Depth of Pour](#)
[CFB2G25R - 2-Gang CFB Series Box for Round Covers, 3.25" Minimum Depth of Pour](#)
[CFB4G30R - 4-Gang CFB Series Box for Round Covers, 3.75" Minimum Depth of Pour, Corrosion Resistant Paint](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
WDK-CFB8RCVRR2-SPEC-EN | REV 5/2023