




## Kellems Wire Managent, Cord Connector, Non-Metallic, .37-.50", 3/4", Gray

By Hubbell Wiring Device-Kellems  
Catalog # [HBL10CM35S](#)

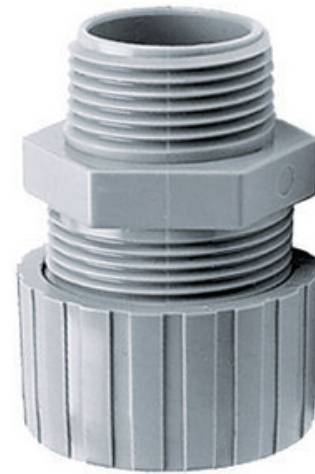

Kellems® Cord Connector, Non-Metallic, .37-.50", 3/4"

### Features

- Strain relief and a Watertight seal

### Application

Straight Male

### General

Color	Gray
Environmental Conditions	Suitable For Use In Wet Locations When Used With A Listed Nylon Washer Between Box And Fitting.
Item Type	Cord Connectors
Material	Nylon
Material - Mounting Hardware	Locknut or Tapped Opening
OEM Brand Name	Hubbell Wiring Device-Kellems
Temperature Rating	Minimum -30 Deg F to 225 Deg F (-43 Deg C to 107 Deg C)
UPC	783585808031

### Dimensions

Display Size 3/4" NPT

### Conductor Related

Conductor Range	0.38-0.5 in (9.5-12.7 mm)
Number Of Conductors	Single

### Logistics

Carton Quantity 10

### Product Assets

[Catalog Page - Wiring\\_Catalog\\_BB51\\_CatPage](#)  
[Catalogs - Wiring Full Catalog](#)  
[Literature - WIRING\\_WLFVM034](#)  
[Literature - Wiring\\_WLFVM032](#)  
[Literature - Wiring\\_WLBVM044](#)  
[Literature - Hubbell Marine Full Line Catalog](#)  
[Literature - Pulp & Paper Solutions](#)  
[Warranty - Industrial & Commercial Products](#)

### Related Products

[HBL10CM41S - Kellems Wire Managent, Cord Connector, Non-Metallic, .62-.75", 1", Gray](#)  
[HBL10CM22S - Kellems Wire Managent, Cord Connector, Non-Metallic, .25-.37", 1/2", Gray](#)  
[HBL10CM37S - Kellems Wire Managent, Cord Connector, Non-Metallic, .62-.75", 3/4", Gray](#)  
[HBL10CM23S - Kellems Wire Managent, Cord Connector, Non-Metallic, .37-.50", 1/2", Gray](#)  
[HBL10CM36S - Kellems Wire Managent, Cord Connector, Non-Metallic, .50-.62", 3/4", Gray](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
WDK-HBL10CM35S-SPEC-EN | REV 5/2023