




Kellems Wire Managent, Cord Connector, Non-Metallic, .62-.75", 3/4", Gray

By Hubbell Wiring Device-Kellems
Catalog # [HBL10CM37S](#)

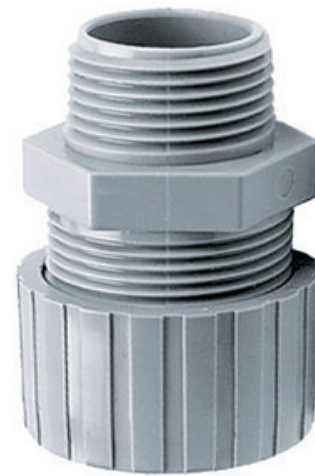

Kellems® Cord Connector, Non-Metallic, .62-.75", 3/4"

Features

- Strain relief and a Watertight seal

Application

Straight Male

General

Color	Gray
Environmental Conditions	Suitable For Use In Wet Locations When Used With A Listed Nylon Washer Between Box And Fitting.
Item Type	Cord Connectors
Material	Nylon
Material - Mounting Hardware	Locknut or Tapped Opening
OEM Brand Name	Hubbell Wiring Device-Kellems
Temperature Rating	Minimum -30 Deg F to 225 Deg F (-43 Deg C to 107 Deg C)
UPC	783585808055

Dimensions

Display Size 3/4" NPT

Conductor Related

Conductor Range	0.63-0.75 in (15.9-19.1 mm)
Number Of Conductors	Single

Logistics

Carton Quantity 10

Product Assets

[Catalog Page - Wiring_Catalog_BB51_CatPage](#)
[Catalogs - Wiring Full Catalog](#)
[Literature - WIRING_WLFVM034](#)
[Literature - Wiring_WLFVM032](#)
[Literature - Wiring_WLBVM044](#)
[Literature - Hubbell Marine Full Line Catalog](#)
[Literature - Pulp & Paper Solutions](#)
[Warranty - Industrial & Commercial Products](#)

Related Products

[HBL10CM23S - Kellems Wire Managent, Cord Connector, Non-Metallic, .37-.50", 1/2", Gray](#)
[HBL10CM41S - Kellems Wire Managent, Cord Connector, Non-Metallic, .62-.75", 1", Gray](#)
[HBL10CM36S - Kellems Wire Managent, Cord Connector, Non-Metallic, .50-.62", 3/4", Gray](#)
[HBL10CM35S - Kellems Wire Managent, Cord Connector, Non-Metallic, .37-.50", 3/4", Gray](#)
[HBL10CM22S - Kellems Wire Managent, Cord Connector, Non-Metallic, .25-.37", 1/2", Gray](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
WDK-HBL10CM37S-SPEC-EN | REV 5/2023