


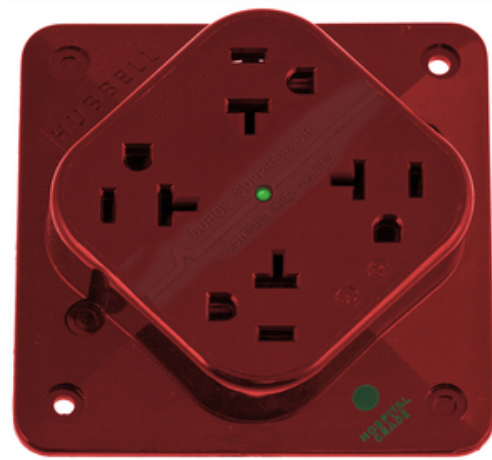

Straight Blade Devices, 4-Plex Receptacle, Commercial Grade, Surge Protected, 20A 125V, 2-Pole 3-Wire Grounding, 5-20R, Red

By Hubbell Wiring Device-Kellems
Catalog # [HBL420HRS](#)



Straight Blade Devices, 4-Plex Receptacle, Commercial Grade, Surge Protected, 20A 125V, 2-Pole 3-Wire Grounding, 5-20R, Red

Application

4-Plex Hospital Grade

General

Color	Red
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	4-PLEX
Material	Polycarbonate
Material - Mounting Hardware	Screw Mounting
Number Of Poles	2-Pole
OEM Brand Name	Hubbell Wiring Device-Kellems
Performance	<ul style="list-style-type: none"> • Electrical - Frequency - 60Hz • Electrical - Protection Modes - Normal and Common Modes • Electrical - Response Time - Approximately 5 ns • Electrical - Transient Suppression - Peak Energy (10 X 100 μs), Peak Current (8 X 20 μs) • Electrical - Voltage - 20V AC + 10% - 15% • Environmental - Flammability - UL 94V-2 • Environmental - Operating Temperature - -40°F to 140°F (-40°C to 60°C)
Series	Hospital Grade
Type	4-Plex
UPC	783585252353

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Amperage Rating	20 A
Connectivity	Back Wired Screw Terminals
Current / Amperage Rating	20 A

Conductor Related

Number Of Wires	3-Wire Grounding
Wire Size	#14 AWG to #12 AWG

Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none"> • Certified to CSA 22.2, No. 42 File 285 • Listed to UL Standard 498 File E2186
Nema Rating	5-20R

Logistics

Carton Quantity	5
-----------------	---

Product Assets

[Catalog Page - Wiring N-13 Catalog page](#)
[Catalog Page - Wiring A-28 Catalog Page](#)
[Catalog Page - Wiring M10 Catalog page](#)
[Catalogs - Wiring Full Catalog](#)
[Engineering Drawing - HBL420HRS AutoCAD Drawing](#)
[Installation Manuals - WIRING_B04578H02_INSTALLINST](#)
[Literature - WLBD026_Duct Products Brochure_WEB](#)
[Literature - SpikeShield® Power Quality Surge Protective Devices](#)
[Sales Drawings - WDK_HBL420_DRAWING_PDF](#)
[Warranty - Industrial & Commercial Products](#)

Related Products

[HBL420HR - Straight Blade Devices, Receptacles, 4- Plex, Hospital Grade, 2-Pole 3-Wire Grounding, 20A 125V, 5-20R, Red, Single Pack](#)
[HBL415HR - Straight Blade Devices, Receptacles, 4- Plex, Hospital Grade, 2-Pole 3-Wire Grounding, 15A 125V, 5-15R, Red, Single Pack](#)
[HBL4APR - Straight Blade Devices, Accessories, 4-Plex Adapter Plate for 1 and 2 Gang device boxes, Red, Single Pack](#)

Current Rating	20 A
Phase	Single Phase
Voltage Rating	125 V
Voltage Rating Description	125 V
Wattage	2500



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
WDK-HBL420HRS-SPEC-EN | REV 5/2023