

Heavy Duty Products, IEC Pin and Sleeve, Inlet, Switched, 60A 480V AC, 2-Pole 3-Wire Grounding, NEMA 4X/IP69K

By Hubbell Wiring Device-Kellems

Catalog # [HBLS360B7W](#)

IEC Pin and Sleeve Switched Inlet, 60A


Features

- Mates with existing installed base of IEC 60309-2 pin and sleeve devices
- Approved as a disconnecting means for motor circuits and branch circuits
- UL Type 4X, 12 and IP69k environmental ratings
- Impact and corrosion-resistant PBT that is color coded by voltage
- Unswitched ground and power indicating LED lights

Conductor

Number Of Wires	3-Wire
Number Of Poles	2-Pole

Current

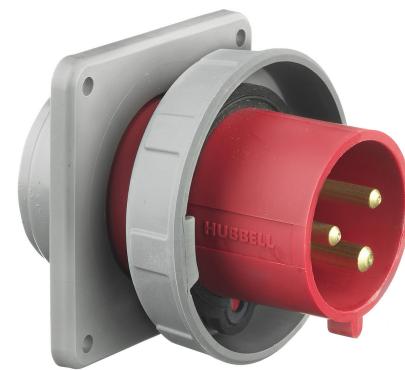

Current / Amperage Rating	60 A
Amperage Rating	60 A
Voltage Rating Description	480 VAC
Voltage Rating	480 VAC

General

Type	Watertight Inlet
Series	Advantage® Series
UPC	783585479248
Style	IP69k NEMA 4X
Color	Red

Product Assets

[Catalog \[English\]](#)
[Installation Manual \[French, English\]](#)