

Heavy Duty Products, Pin and Sleeve Devices, Switched, IEC 309, Male Plug, 30A 125/250V, 3-Pole 4-Wire Grounding, NEMA 4X/IP67, Watertight

By Hubbell Wiring Device-Kellems
Catalog # [HBLS430P12W](#)

Heavy Duty Pin and Sleeve Devices, Switched, IEC 309 Male Plug, 30A 125/250V, 3-Pole 4-Wire Grounding, NEMA 4X/IP67, Watertight

Features


- Mates with existing installed base of IEC 60309-2 pin and sleeve devices
- Approved as a disconnecting means for motor circuits and branch circuits
- UL Type 4X, 12 and IP69k environmental ratings
- Impact and corrosion-resistant PBT that is color coded by voltage
- Unswitched ground and power indicating LED lights

General

Catalog Number	HBLS430P12W
Color	Orange
Number Of Poles	3-Pole
Series	Advantage Switch-Rated
Style	IP69k NEMA 4X
Type	Watertight Plug
UPC	783585550831

Electrical Ratings

Amperage Rating	30 A
-----------------	------

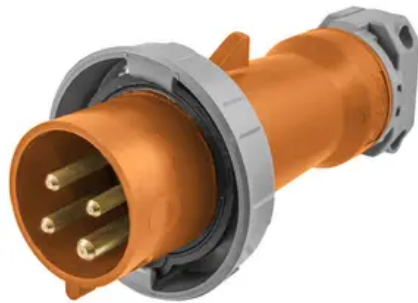

Current / Amperage Rating	30 A
Voltage Rating	125/250 VAC
Voltage Rating Description	125/250 VAC

Conductor Related

Number Of Wires	4-Wire
-----------------	--------

Logistics

Carton Quantity	10
-----------------	----

Product Assets

- [Catalogs - WDK Catalog Full 2024](#)
- [Engineering Drawing - HBLS430P12W AutoCAD Drawing](#)
- [Installation Manuals - WIRING_PD1303_INSTALLINST](#)
- [Literature - Food Processing Guide](#)
- [Literature - PULP & PAPER SOLUTIONS](#)
- [Literature - Pulp & Paper Solutions](#)
- [Literature - Industrial Solutions](#)
- [Sales Drawings - WDK_HBLS430P12W_DRAWINGS_PDF](#)
- [Specifications - HBLS430P12W](#)
- [Warranty - Industrial & Commercial Products](#)
- [Video - Advantage Series Switch-Rated Pin & Sleeve](#)