

Copper Solutions, Patch Cords,
NEXTSPEED, Cat 6, Slim, 20'
Length, White

By Hubbell Wiring Device-Kellems
Catalog # [HC6W20](#)

Copper Solutions, Patch Cords, NEXTSPEED, Cat 6, Slim, 20'
Length, White

Features


- Third Party Verified Category 6 Component
- Plug Optimized For High Density Switch Ports
- TSB-155 10 Gig Support
- Qualified to 150% of 802.3bt PoE Current Level

Performance

- Mechanical - Cable to plug tensile strength - 20+ lbs.
- Mechanical - Mating Cycles - 2000+

General

Attenuation	.1dB
Boot Type	PVC
Catalog Number	HC6W20
Color	White
EU RoHS Indicator	Yes
Item Type	NEXTSPEED Category 6 and 5e Patch Cords
Material - Insulation	Flame Redardant PVC
Material - Jacket	Flame Redardant PVC
Plug Type	RJ45
Specifications	<ul style="list-style-type: none">• Conductor - 24AWG UTP• Contact Plating - 50 micro-inch Gold with 100 micro-inch under plating• Jacket - Flame-Retardant PVC-CM Rated• OD - 0.224 in.• Plug Body - Plycarbonate UL 94V-0

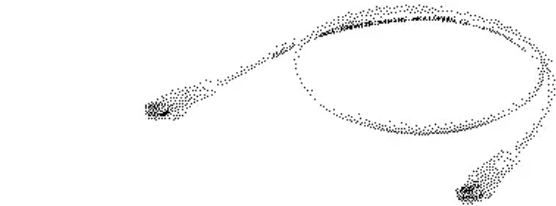

Temperature Rating	• Plug Boot - Polycarbonate UL 94V-0
Type	Per TIA
UPC	Standard 662620233611

Dimensions

Length	20 ft
Outside Diameter	0.218

Electrical Ratings

Voltage Rating	300V AC kV
----------------	------------

Conductor Related

Conductor Stranding	Stranded
Conductor Type	Copper
Number of Conductors	8-Conductor
Wire Size	#24 AWG

Certifications And Compliance

Industry Standard(s)	<ul style="list-style-type: none">• ANSI/TIA/EIA-568-C.2 Category 6 Component• ISO 11801/60603-7-41 Category 6 Component
----------------------	---

Product Assets

[Catalog Page - PREM D5 CatalogPage](#)
[Catalogs - Premise Wiring Catalog](#)
[Catalogs - WDK Catalog Full 2024](#)
[Specifications - HC6W20](#)
[Warranty - Industrial & Commercial Products](#)