




iStation Modules, 15-Pin, XLR, 3.5 MM Stereo Jack, Unloaded, 2-Unit, Office White

By Hubbell Wiring Device-Kellems
Catalog # [IMB153X2OW](#)

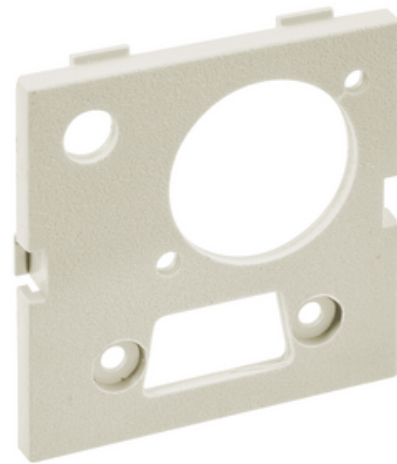

iStation Modules, 15-Pin, XLR, 3.5 MM Stereo Jack, Unloaded, 2-Unit, Office White

Application

15/9 Pin/HDMI, Pro AV, 3.5mm

General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION Front-Loading Modules
Material - Mounting Hardware	Snap-On- Snap-Fit
Style	3.5mm Stereo Jack
Temperature Rating	Per TIA
Type	VGA
UPC	662620210001

Dimensions

Display Size	Standard Sized Product
--------------	------------------------

Electrical Ratings

Connectivity	Plug-N-Play
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

Logistics

Carton Quantity	20
-----------------	----

Product Assets

[Catalog Page - Wiring Z-14 Catalog page](#)
[Catalogs - Wiring Full Catalog](#)
[Literature - Connexion 2.0 Zone Distribution System](#)
[Warranty - Industrial & Commercial Products](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
WDK-IMB153X2OW-SPEC-EN | REV 5/2023