




# Field Attachable Micro-Quick Control Connectors, Female Angled Plug, 3 Wire, Insulation Displacement

By Hubbell Wiring Device-Kellems  
Catalog # [MCMA131DC](#)

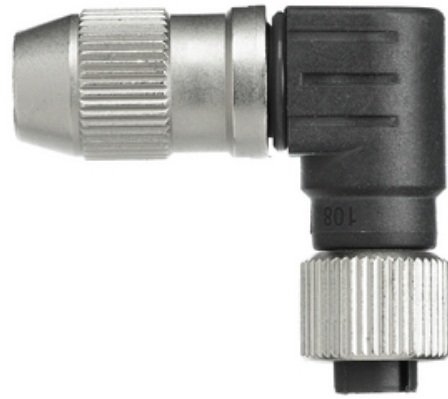

Field Attachable Micro-Quick Control Connectors, Female Angled Plug, 3 Wire, Insulation Displacement

## Features

- Strain relief bushing protects terminations
- Wire Guide for virtually toolless termination
- Insulation displacement contacts are made of Copper Alloy

## Application

Quick Connect/Disconnect Signal and Control

## General

Color	Black
EU RoHS Indicator	Yes
Item Type	Female Angle Plug
OEM Brand Name	Hubbell Wiring Device-Kellems
Performance	<ul style="list-style-type: none"><li>• Electrical - Amperage - 3A</li><li>• Electrical - Cable Diameters - .160" to .211"</li><li>• Electrical - Voltage Rating - 32V AC/DC</li><li>• Electrical - Wire Range - #22 AWG max.</li><li>• #24 AWG min.</li><li>• Environmental - Ingress Protection - IP66 Suitability</li><li>• Environmental - Operating Temperature - -20°C to 110°C</li></ul>
Temperature Rating	-20 Deg C to 105 Deg C
UPC	783585226712

## Dimensions

Diameter Live Part .67"

## Conductor Related

Conductor Type Copper  
Number Of Conductors 3-Pole

## Certifications and Compliance

Industry Standard(s)

- CSA Certified, C22.2 No. 182.3 and CSA C22.2 No. 94.2-07
- UL 2238 and UL50E, File No. E192071

## Logistics

Carton Quantity 25

## Product Assets

[Installation Manuals - WIRING\\_PD1939\\_INSTALLINST](#)  
[Literature - WIRING\\_WLFVM034](#)  
[Literature - Pulp & Paper Solutions](#)  
[Sales Drawings - WDK\\_MCMA131DC\\_DRAWING\\_PDF](#)  
[Warranty - Industrial & Commercial Products](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
WDK-MCMA131DC-SPEC-EN | REV 5/2023