




# Field Attachable Micro-Quick Control Connectors, Male Straight, 4 Wire, Insulation Displacement

By Hubbell Wiring Device-Kellems  
Catalog # [MIMS14IDCL](#)

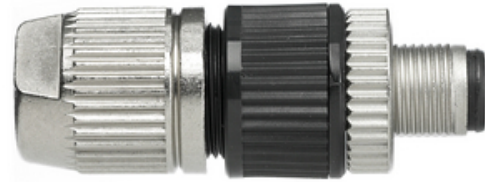

Field Attachable Micro-Quick Control Connectors, Male Straight, 4 Wire, Insulation Displacement

## Features

- Strain relief bushing protects terminations
- Wire Guide for virtually toolless termination
- Insulation displacement contacts are made of Copper Alloy

## Application

Quick Connect/Disconnect Signal and Control

## General

Color	Black
EU RoHS Indicator	Yes
Item Type	Male Straight In-Line Plug
OEM Brand Name	Hubbell Wiring Device-Kellems
Performance	<ul style="list-style-type: none"><li>• Electrical - Amperage - 6A</li><li>• Electrical - Cable Diameters - .22" to .32"</li><li>• Electrical - Voltage Rating - 50V AC/DC</li><li>• Electrical - Wire Range - #18 AWG max., #22 AWG min.</li><li>• Environmental - Ingress Protection - IP66 Suitability</li><li>• Environmental - Operating Temperature - -20°C to 110°C</li></ul>
Temperature Rating	-20 Deg C to 105 Deg C
UPC	783585226767

## Dimensions

Diameter Live Part .59"

## Conductor Related

Conductor Type Copper  
Number Of Conductors 4-Pole

## Certifications and Compliance

Industry Standard(s)

- CSA Certified, C22.2 No. 182.3 and CSA C22.2 No. 94.2-07
- UL 2238 and UL50E, File No. E192071

## Logistics

Carton Quantity 25

## Product Assets

[Installation Manuals - WIRING\\_PD1939\\_INSTALLINST](#)  
[Literature - WIRING\\_WLFVM034](#)  
[Literature - Pulp & Paper Solutions](#)  
[Sales Drawings - WDK\\_MIMS14IDCL\\_DRAWING\\_PDF](#)  
[Warranty - Industrial & Commercial Products](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
WDK-MIMS14IDCL-SPEC-EN | REV 5/2023